



YCS25RL, Aluminum Sleeve, Staked Cable Stop

By Burndy
Catalog # [YCS25RL](#)

HYSPLICE AL sleeve with staked cable stop, designed to withstand jumper loop tensile and vibration stresses. ANSI C119.4 CLASS 2 (PARTIAL TENSION), 6-1/4 IN L.

Features

- HYSPLICE Sleeve designed to withstand jumper loop tensile and vibration stresses
- Made of aluminum with staked-in cable stop
- Pre-Filled with PENETROX Joint Compound and Capped

Application

For ACSR, All Aluminum 6201, 5005 Compressed And Compact Conductors


Specifications

Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	No
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor - AAAC 5005 Size Range	1/0 (7) AWG
Conductor - AAAC 6201 Size	1/0 (7) AWG
Conductor - AAAC 6201 Size Range	1/0 (7) AWG
Conductor - ACSR Str Size	1/0 (6/1) Raven AWG
Conductor - ACSR Str Size Range	1/0 (6/1) Raven AWG
Conductor - AL Str Size	1/0 (7) AWG
Conductor - AL Str Size Range	1/0 (7) AWG
Conductor - AAAC 5005 Size	1/0 (7) AWG

Configuration

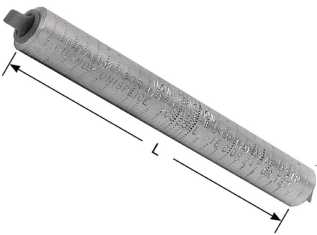

Connector Type Splice

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - Outside Diameter inch	0.8 in
Dimension - L Length Overall mm	158 mm
Package Height	0.000 in
Dimension - B Length inch	3.03 in
Dimension - Length Overall inch	6.22 in

General

Die Index	C or 247
Trade Name	UNISPLICE™
Prefilled Oxide Inhibitor	Y
Sub Brand	UNISPLICE
Plated	N
Type	YCS-RL
UPC 12 Digit	781810014998
UPC 14 Digit GTIN	00781810014998
Material	Aluminum
Plating Type	Unplated
UPC	781810014998

Logistics

Minimum Pack Quantity	25
Carton Quantity	25
Pallet Quantity	9800

Product Assets

[Catalog \[English\]](#)