



YCS26RL, Aluminum Sleeve, Staked Cable Stop

By Burndy
Catalog # [YCS26RL](#)

HYSPLICE AL sleeve with staked cable stop, designed to withstand jumper loop tensile and vibration stresses, Conductor: 1/0 (ACSR, 6201, 5005, AAC)

Features

- Aluminum Sleeve
- Staked Cable Stop

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
UL Listed	No


Conductor

Conductor - AAAC 5005 Size Range	2/0 (7) AWG
Conductor - AAAC 6201 Size Range	2/0 (7) AWG
Conductor - ACSR Str Size Range	2/0 (6/1) Quail AWG
Conductor - AL Str Size Range	2/0 (7) AWG
Conductor - AAAC 5005 Size	2/0 (7) AWG

Configuration

Connector Type	Splice
----------------	--------

Dimensions

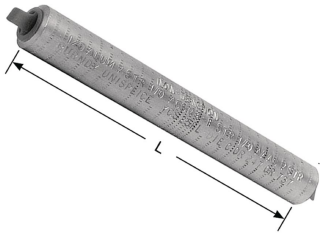

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - B Length inch	2.7 in
Dimension - Outside Diameter inch	0.83 in
Dimension - L Length Overall mm	141 mm
Package Height	0.000 in
Dimension - Length Overall inch	5.56 in

General

Die Index	659
Trade Name	UNISPLICE™
Plated	N
Prefilled Oxide Inhibitor	Y
UPC 12 Digit	781810015018
UPC 14 Digit GTIN	00781810015018
Material	Aluminum
Plating Type	Unplated
UPC	781810015018

Logistics

Minimum Pack Quantity	1
Carton Quantity	25
Pallet Quantity	9800

Product Assets

[Catalog \[English\]](#)