



YCS27RL, Aluminum Loop Splice

By Burndy
Catalog # [YCS27RL](#)

Al Tube UNISPLICE, Loop, 3/0 AWG ACSR/AAAC/AAC

Features

- Aluminum Loop Splice

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor


Conductor - AAAC 6201 Size	3/0 AWG
Conductor - AL Str Size	3/0 AWG
Conductor - AAAC 5005 Size	3/0 AWG
Conductor - ACSR Str Size	3/0 (6/1) Pigeon AWG

Configuration

Connector Type	Splice
----------------	--------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

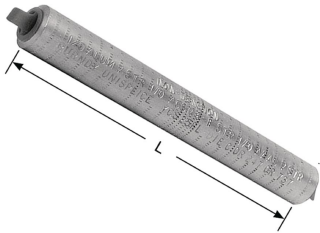

Dimension - L Length Overall	131 mm
Dimension - B Length	2.5 in
Dimension - Outside Diameter	0.91 in
Dimension - Length Overall	5.16 in

General

Plated	N
Trade Name	HYSPLICE™
Die Index	658
UPC	781810171042
Prefilled Oxide Inhibitor	Y
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810171042
UPC 14 Digit GTIN	00781810171042

Logistics

Minimum Pack Quantity	25
Pallet Quantity	7400
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)