


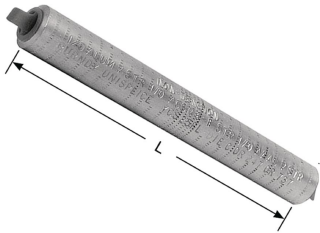

YCS28RL, Aluminum Sleeve, Staked Cable Stop

By Burndy
Catalog # [YCS28RL](#)

Al Jumper sleeve, 4/0 AWG ACSR(6-1),6201(7), 5005(7), AAC(7)



Features

- Aluminum Sleeve
- Staked Cable Stop

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor - AAAC 6201 Size	4/0 AWG
Conductor - ACSR Str Size	4/0 (6/1) Penguin AWG
Conductor - AL Str Size	4/0 AWG
Conductor - AAAC 5005 Size	4/0 AWG

Configuration

Connector Type	Splice
----------------	--------

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.

Dimension - B Length inch	2.44 in
Dimension - Outside Diameter inch	1.02 in
Dimension - L Length Overall mm	131 mm
Package Height	0.000 in
Dimension - Length Overall inch	5.16 in

General

Die Index	654
Trade Name	UNISPLICE™
Plated	N
Prefilled Oxide Inhibitor	Y
UPC 12 Digit	781810820506
UPC 14 Digit GTIN	00781810820506
Material	Aluminum
Plating Type	Unplated
UPC	781810820506

Logistics

Minimum Pack Quantity	25
Carton Quantity	25
Pallet Quantity	7400

Product Assets

[Catalog \[English\]](#)