



YCS321RL, Aluminum Sleeve, Staked Cable Stop

By Burndy
Catalog # [YCS321RL](#)

HYSPLICE AL sleeve with staked cable stop, designed to withstand jumper loop tensile and vibration stresses. ANSI C119.4 CLASS 2 (PARTIAL TENSION), Index:655.

Features

- HYSPLICE Sleeve designed to withstand jumper loop tensile and vibration stresses
- Made of aluminum with staked-in cable stop
- Pre-Filled with PENETROX Joint Compound and Capped

Application

For ACSR, All Aluminum 6201, 5005 Compressed And Compact Conductors

Specifications


Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor - ACSR Str Size	336.4 (18/1) Merlin
Conductor - AL Str Size	336.4

Configuration

Connector Type	Splice
----------------	--------

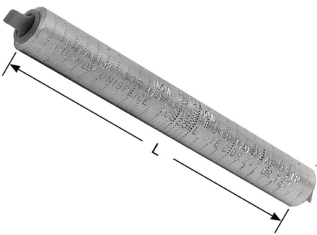

Dimensions

Dimension - B Length inch	2.25 in
Dimension - Outside Diameter inch	1.13 in
Dimension - L Length Overall mm	131 mm
Dimension - Length Overall inch	5.16 in

General

Sub Brand	UNISPLICE
Die Index	655
Trade Name	UNISPLICE™
Plated	N
Type	YCS-RL
Prefilled Oxide Inhibitor	Y
UPC 12 Digit	781810015124
UPC 14 Digit GTIN	00781810015124
Material	Aluminum
Plating Type	Unplated
UPC	781810015124

Logistics

Minimum Pack Quantity	25
Carton Quantity	25
Pallet Quantity	6000

Product Assets

[Catalog \[English\]](#)