


YCS33RG1, Aluminum Splice

By Burndy
Catalog # [YCS33RG1](#)

Aluminium Hysplice, 336.4 kcmil (26-7, 30-7), 193 Index

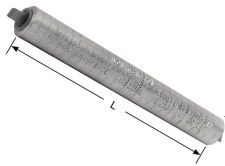

Features

- Aluminum Splice

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor - ACSR Str Size	• 336.4 (26/7) Linnet • 336.4 (30/7) Oriole
---------------------------	---

Configuration

Connector Type	Splice
----------------	--------

Dimensions

Dimension - B Length inch	2.56 in
Dimension - Outside Diameter inch	1.06 in

Dimension - L Length Overall mm	133 mm
Dimension - Length Overall inch	5.25 in

General

Die Index	193
Trade Name	HYSPLICE™
Plated	N
Prefilled Oxide Inhibitor	Y
UPC 12 Digit	781810015056
UPC 14 Digit GTIN	00781810015056
Material	Aluminum
Plating Type	Unplated
UPC	781810015056

Logistics

Minimum Pack Quantity	1
Carton Quantity	25
Pallet Quantity	7400

Product Assets

[Catalog \[English\]](#)