



YCS341RL, Aluminum Sleeve, Staked Cable Stop

By Burndy
Catalog # [YCS341RL](#)

HYSPLICE AL sleeve with staked cable stop, designed to withstand jumper loop tensile and vibration stresses. ANSI C119.4 CLASS 2 (PARTIAL TENSION), 5-5/8 IN L

Features

- Aluminum Sleeve
- Staked Cable Stop

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
UL Listed	No

Conductor


Conductor - ACSR Str Size	397.5 Kcmil, 336.4 kcmil
Conductor - AL Str Size	400 kcmil

Configuration

Connector Type	Splice
----------------	--------

Dimensions

Dimension - Outside Diameter	1.13 in
------------------------------	---------

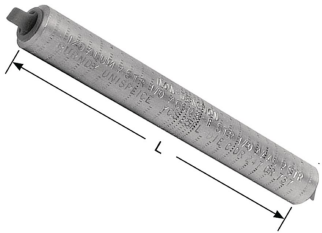

Dimension - L Length Overall	141 mm
Dimension - Length Overall	5.56 in

General

Die Index	327
Trade Name	UNISPLICE™
Plated	N
Prefilled Oxide Inhibitor	Y
UPC 12 Digit	781810015131
UPC 14 Digit GTIN	00781810015131
Material	Aluminum
Plating Type	Unplated
UPC	781810015131

Logistics

Minimum Pack Quantity	1
Carton Quantity	25
Pallet Quantity	3600

Product Assets

[Catalog \[English\]](#)