


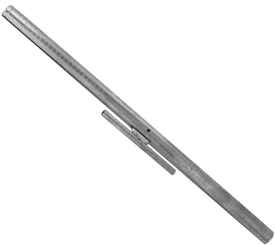

YDS36R, 2-piece, ACSR Splice, includes inner and outer sleeves

By Burndy
Catalog # [YDS36R](#)



2-piece, full tension ACSR splice consists of steel inner sleeve and AL outer sleeve, Inner Sleeve: 7.88 IN L, Outer Sleeve: 26.38 IN L

Features

- 2-Piece, Full Tension HYSPLICE consists of aluminum outer sleeve and steel inner sleeve
- Tapered out sleeve provides gradual transition of stress
- Filler hole provided for PENETROX Joint Compound
- Sizes 1/0 and larger come supplied with plugs for filler hole

Application

For ACSR, Compressed And Compact Conductors

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - ACSR Str Size	477.0 (26/7) Hawk kcmil
Conductor - ACSR Str Size	477.0 (26/7) Hawk kcmil
Range	
Conductor Type	• ACSR C Str-Size • AL C Str-Size

Configuration

Connector Type	Splice
----------------	--------

Dimensions

Package Height	0.000 in
----------------	----------

Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall	200 mm
mm	
Dimension - Steel Sleeve	7.875 in
Length inch	
Dimension - Aluminum Sleeve	26.375 in
Length inch	
Dimension - Length Overall	7.89 in
inch	

General

Trade Name	HYSPLICE™
Die Index	• 350 • 261
Die Index - Element A	350
Die Index - Element B	261
Prefilled Oxide Inhibitor	Y
Plated	N
Sub Brand	HYSPLICE
UPC	781810015759
Type	YDS-R Set
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810015759
UPC 14 Digit GTIN	00781810015759

Logistics

Minimum Pack Quantity	10
Pallet Quantity	350
Carton Quantity	10

Product Assets

[Catalog \[English\]](#)