




BURNDY

YDS43R45RS, 2-piece, ACSR Splice, includes inner and outer sleeves

By Burndy

Catalog # [YDS43R45RS](#)

Two-piece, full tension ACSR splice consists of steel inner sleeve and aluminum outer sleeve. ANSI C119.4 Class 1 (Full Tension)

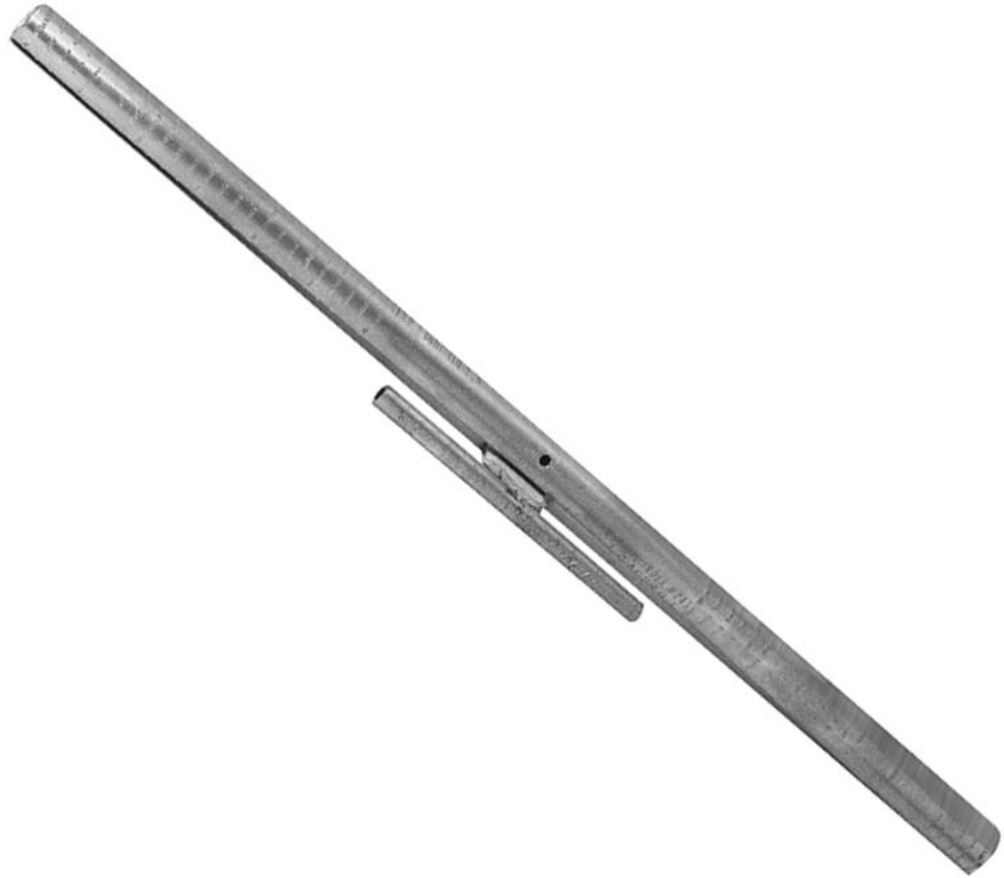

Features

- 2-Piece ACSR Splice
- Includes inner and outer sleeves

Specifications

Certification - ETL

No

Certification - UL Recognized

No

Standards - RoHS Compliance Status

CM

Certification - cULus
No
UL Listed
No
Certification - CSA Approved
No

Conductor

Conductor - AL Str Size
636(26.7)kcmil
Conductor - AL Str Size Range
636 kcmil
Conductor Type

- ACSR C Str-Size
- AL C Str-Size

Conductor - ACSR Str Size
636 (26/7) Grosbeak kcmil
Conductor - ACSR Str Size Range
636 (26/7) Grosbeak kcmil

Configuration

Connector Type
Splice

Dimensions

Dimension - Aluminum Sleeve Length inch
32.50 in
Dimension - L Length Overall mm
229 mm
Dimension - Steel Sleeve Length inch
8 in
Dimension - Length Overall inch
9 in

General

Plated
N
Trade Name
HYSPLICE™
Die Index

- 320
- 319

Die Index - Element A
319
Die Index - Element B
320
UPC
781810096628
Prefilled Oxide Inhibitor
Y
Material
Aluminum
Plating Type
Unplated
UPC 12 Digit
781810096628
UPC 14 Digit GTIN
00781810096628

Logistics

Minimum Pack Quantity
1
Pallet Quantity
252
Carton Quantity
3

Product Assets



A Hubbell brand
© 2026 Hubbell Incorporated. All rights reserved
BRDY-YDS43R45RS-SPEC-EN | REV 5/2026