


YF1/020IDL, Covered Ferrule For 1/0 AWG

By Burndy
Catalog # [YF1/020IDL](#)

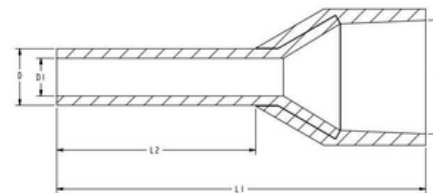

Covered Ferrule For 1/0 AWG.

Features

- Made of electrolytic copper, tin plated
- Smooth funnel entry to make wire insertion easier
- Secure contacting even after multiple reconections
- Long-term contact resistance
- No fraying of strands
- No breakage of wire strands when wire is bent, under stress, or in vibration environment
- UL listed per UL486F requirements
- RoHS Compliant

Application

For Use On Copper Conductor

General

Catalog Number	YF1/020IDL
Connector Type	End Termination
EU RoHS Indicator	Yes
Insulation	Y
Material	Copper
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	FERRULES
Type	Bootlace Ferrule
UPC	621945622586

Dimensions

Dimension - D inch	0.43 in
Dimension - D1 inch	0.41 in

Dimension - D2 inch	0.59 in
Dimension - Length Overall inch	1.42 in

Conductor Related

Conductor - Copper Solid Size	1/0 AWG
Conductor - Copper Str Size	1/0 AWG
Conductor Size	1/0 AWG

Certifications And Compliance

Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - Industry Standards	UL486
Met	
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Carton Quantity	50
Minimum Pack Quantity	50

Product Assets

[Catalogs - BURNDY Master Catalog - Section B - Small Terminals](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - 50111876](#)
[Specifications - YF1020IDL](#)