




# YF1018IWL, Covered Ferrule For 10 AWG

By Burndy  
Catalog # YF1018IWL

Covered Ferrule For 10 AWG

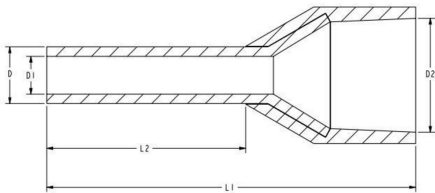

## Features

- Made of electrolytic copper, tin plated
- Smooth funnel entry to make wire insertion easier
- Secure contacting even after multiple reconnections
- Long-term contact resistance
- No fraying of strands
- No breakage of wire strands when wire is bent, under stress, or in vibration environment
- UL listed per UL486F requirements
- RoHS Compliant

## Application

For Use On Copper Conductor

## Specifications

|                                |       |
|--------------------------------|-------|
| Certification - ETL            | No    |
| Certification - UL Recognized  | No    |
| Standards - Industry Standards | UL486 |
| Met                            |       |
| Standards - RoHS Compliance    | CM    |
| Status                         |       |
| Certification - cULus          | No    |
| EU RoHS Indicator              | Yes   |
| UL Listed                      | Yes   |
| Certification - CSA Approved   | No    |

## Conductor

|                               |        |
|-------------------------------|--------|
| Conductor Size                | 10 AWG |
| Conductor - Copper Solid Size | 10 AWG |
| Conductor - Copper Str Size   | 10 AWG |

## Configuration

|                |                 |
|----------------|-----------------|
| Connector Type | End Termination |
|----------------|-----------------|

## Dimensions

|                            |           |
|----------------------------|-----------|
| Dimension - D1 inch        | 0.14 in   |
| Dimension - D2 inch        | 0.25 in   |
| Dimension - D inch         | 0.15 in   |
| Package Height             | 0.000 in  |
| Package Weight             | 0.000 lb. |
| Package Length             | 0.000 in  |
| Package Width              | 0.000 in  |
| Dimension - Length Overall | 1.02 in   |
| inch                       |           |

## General

|              |                      |
|--------------|----------------------|
| Plated       | Y                    |
| UPC          | 621945622012         |
| Type         | Bootlace Ferrule     |
| Insulation   | Y                    |
| Sub Brand    | FERRULES             |
| Material     | Copper               |
| Plating Type | Tin - Electro Plated |

## Logistics

|                       |     |
|-----------------------|-----|
| Minimum Pack Quantity | 100 |
| Carton Quantity       | 100 |

## Product Assets

[Catalog \[English\]](#)