




YF1209IDL, Covered Ferrule For 12 AWG

By Burndy
Catalog # [YF1209IDL](#)

Covered Ferrule For 12 AWG

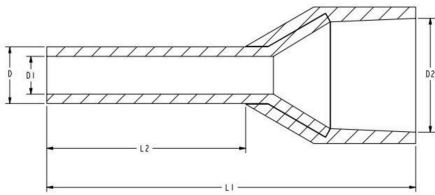

Features

- Made of electrolytic copper, tin plated
- Smooth funnel entry to make wire insertion easier
- Secure contacting even after multiple reconnections
- Long-term contact resistance
- No fraying of strands
- No breakage of wire strands when wire is bent, under stress, or in vibration environment
- RoHS Compliant

Application

For Use On Copper Conductor

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
EU RoHS Indicator	Yes
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor Size	12 AWG
Conductor - Copper Solid Size	12 AWG
Conductor - Copper Str Size	12 AWG

Configuration

Connector Type

End Termination

Dimensions

Dimension - D1 inch	0.11 in
Dimension - D2 inch	0.19 in
Dimension - D inch	0.13 in
Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - Length Overall	0.67 in
inch	

General

Plated	Y
UPC	621945622340
Type	Bootlace Ferrule
Insulation	Y
Sub Brand	FERRULES
Material	Copper
Plating Type	Tin - Electro Plated

Logistics

Minimum Pack Quantity	500
Carton Quantity	500

Product Assets

[Catalog \[English\]](#)