




YFA34CR2, Copper - Lug Limiter

By Burndy
Catalog # [YFA34CR2](#)

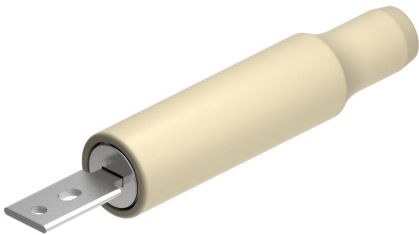

Limiter Lug Assembly, With DURICOMP Shell & Rubber Sleeve,
500 kcmil, 250 V, 13.62" L

Features

- Copper Lug Limiter Assembly with Shell and Rubber Sleeve

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	500 kcmil
-----------------------------	-----------

Configuration

Physical Attribute - Number of Holes	2
Connector Type	Limiter

Dimensions

Dimension - Pad Width inch	1.53 in
Package Height	0.000 in
Package Weight	0.000 lb.
Dimension - Width inch	2.38 in
Package Length	0.000 in
Package Width	0.000 in

Dimension - Z inch	1.34 in
Dimension - B Length inch	2.44 in
Dimension - D inch	2.75 in
Dimension - N inch	0.50 in
Dimension - Hole Size inch	0.44 in
Dimension - Length Overall inch	13.62 in

General

Feature - Barrel Style	Chamfered
Plated	Y
Color Code	Brown
Insulation Type	Rubber
Die Index	20
UPC	781810000854
Insulation	Y
Plating Type	Tin
UPC 12 Digit	781810000854
UPC 14 Digit GTIN	00781810000854

Logistics

Minimum Pack Quantity	2
Pallet Quantity	400
Carton Quantity	8

Product Assets

[Catalog \[English\]](#)