




BURNDY

YGA6CTC10 Compression Grounding Lug, #6 Sol/Str, #10 Stud

By Burndy
Catalog # [YGA6CTC10](#)
Grounding Irreversible Compression Terminals.

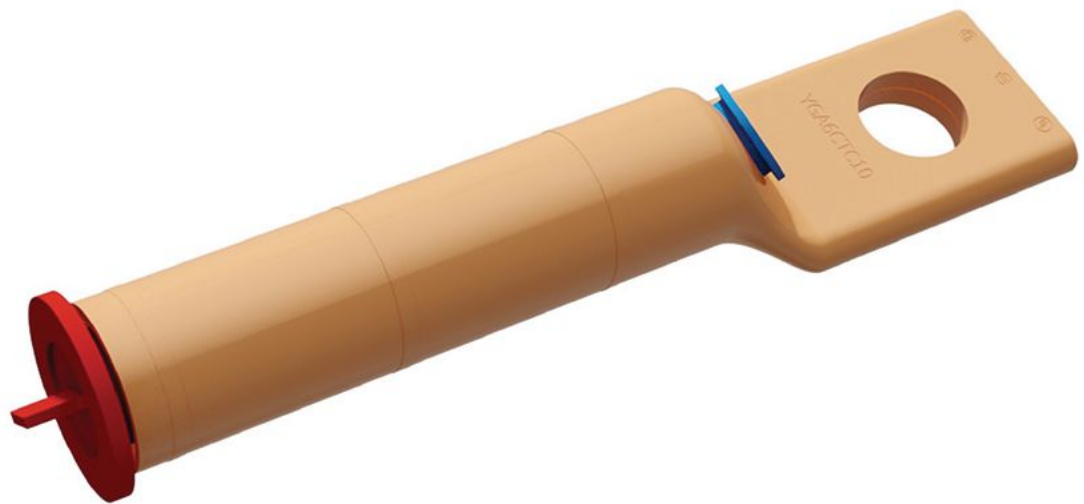

Features

- Irreversible compression ground terminal specifically designed for grounding applications
- Each connector has an inspection probe hole to ensure proper cable insertion
- UL467 Listed
- Acceptable for Direct Burial in earth or concrete
- UL486A Listed
- Prefilled with PENETROX™ compound and strip sealed

Specifications

Certification - ETL
No

Certification - UL Recognized
No
Standards - Industry Standards Met

- UL467
- UL468A-468B

Standards - RoHS Compliance Status
CM
Certification - cULus
No
Certification - UL Listed Direct Burial
Yes
Industry Standard(s)

- UL 467
- Direct Burial

UL Listed
Yes
Certification - CSA Approved
No

Conductor

Conductor - Copper Solid Size
6
Conductor - Copper Solid Size Range
6
Conductor Type

- CU C Solid-Size
- CU C Str-Size

Conductor - Copper Str Size Range
6 Sol / 6 AWG
Conductor - Copper Str Size
6 Sol./6 Str.

Configuration

Physical Attribute - Number of Crimps Required
2
Connector Type
Terminal

Dimensions

Dimension - Pad Width inch
0.42 in
Dimension - Bolt Hole Size inch
0.20 in
Package Height
0.000 in
Dimension - B Length fraction
1-1/8 in
Package Weight
0.000 lb.
Package Length
0.000 in
Package Width
0.000 in
Dimension - L Length Overall mm
48 mm
Dimension - B Length inch
1.12 in
Dimension - Outside Diameter inch
0.29 in
Dimension - N inch
0.25 in
Dimension - Hole Size mm
5 mm
Dimension - Hole Size inch
0.21 in
Dimension - Length Overall inch
1.89 in
Dimension - Strip Length inch
1-3/16
Dimension - Stud Size inch
#10

Dimension - Stud Size fraction
1/2

General

Plated
N
Color Code
Blue
Trade Name
HYLUG™
Die Index

- 7
- 374

UPC
781810146026
Type
Terminals
Material
Copper
Plating Type
Unplated
UPC 12 Digit
781810146026
UPC 14 Digit GTIN
00781810146026

Logistics

Minimum Pack Quantity
1
Carton Quantity
100

Product Assets

[Catalog.\[English\]](#)



A Hubbell brand
© 2026 Hubbell Incorporated. All rights reserved
BRDY-YGA6CTC10-SPEC-EN | REV 5/2026