




BURNDY

YGHHHC34C29 Compression Grounding C-TAP Connector

By Burndy

Catalog # [YGHHHC34C29](#)

Compression ground connector, Material: Copper, Range Run: 300 Kcmil-500 Kcmil; Tap: 3/0 Str-250 Kcmil.

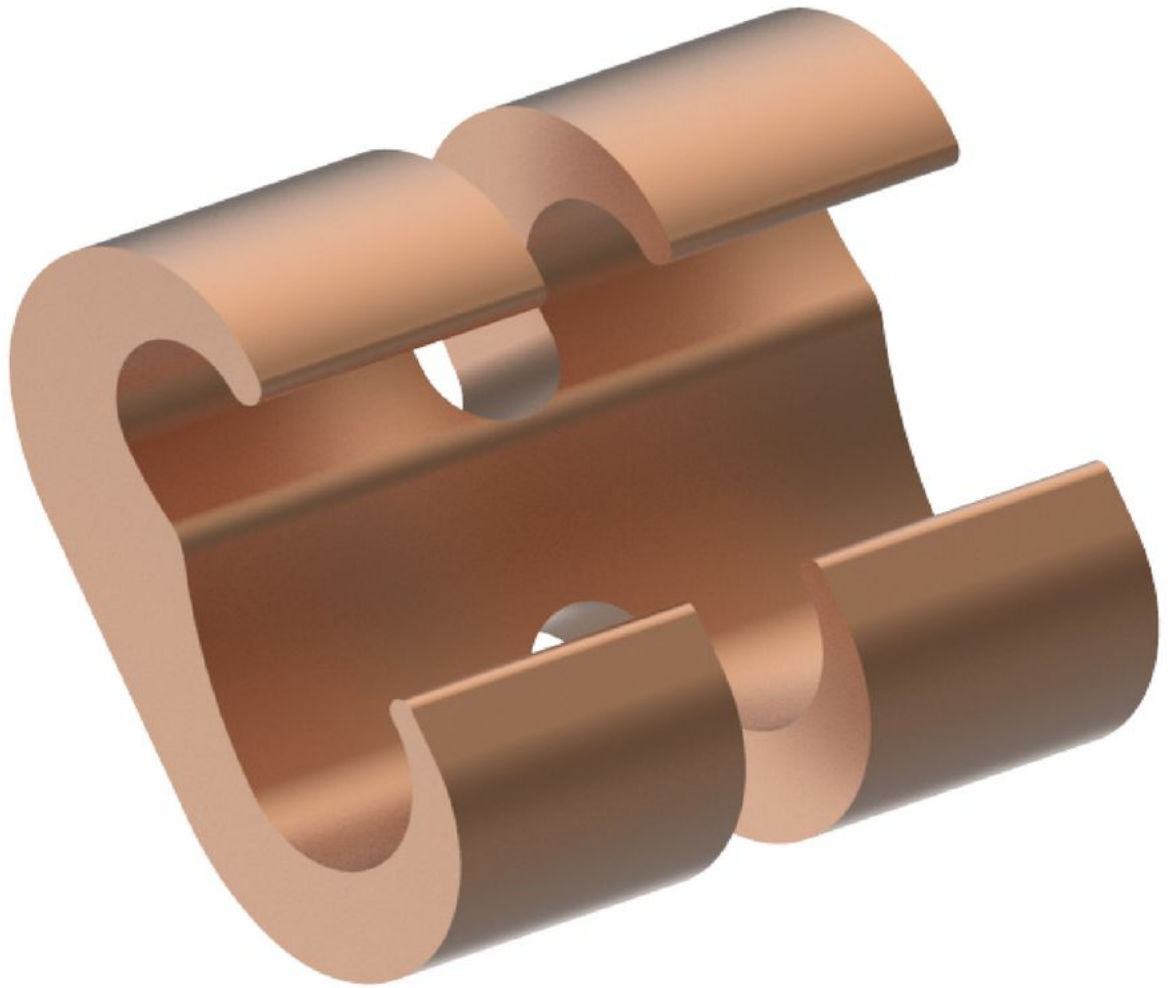

Features

- Double Figure C Connector, C-Shaped opening permits two continuous parallel cables into conductor groove
- Qualified to IEEE-837 2014
- Prefilled with PENETROX compound and strip sealed

Application

For Direct Burial cables

Specifications

Standards - Industry Standards Met

- UL467
- IEEE 837
- IEEE 837 2014 Qualified
- UL 486A-486B

Standards - RoHS Compliance Status
CM

Buy American Compliant
No

EU RoHS Indicator
Contact Manufacturer

Certification - UL Listed Direct Burial
Yes

Industry Standard(s)

- UL 467
- IEEE 837
- IEEE 837 2014 Qualified
- UL 486A-486B

Certification - CSA Approved
[Delete]

Conductor

Conductor - Copper Str Run Range
300 - 500 kcmil
Conductor - Copper Str Tap Range
3/0 Stranded - 250 kcmil

Configuration

Connector Type
Tap

Dimensions

Package Height
0.000 in
Dimension - Height mm
0 mm
Package Weight
0.000 lb.
Package Length
0.000 in
Package Width
0.000 in
Width
2.13 in

General

Plated
N
Trade Name
HYTAP™
Sub Brand
HYTAP
Die Index
1011
UPC
621945456266
Type
Taps
Material
Copper
UPC 12 Digit
621945456266
UPC 14 Digit GTIN
00621945456266

Logistics

Minimum Pack Quantity
1
Pallet Quantity
2400

Carton Quantity
10

Product Assets

[Catalog \[English\]](#)

[Installation Manual \[English\]](#)



A Hubbell brand
© 2026 Hubbell Incorporated. All rights reserved
BRDY-YGHHC34C29-SPEC-EN | REV 5/2026