



**YGHP34C2 Fig. 6 Ground Conn, Cu #4 Sol-#2
Str, 5/8"-3/4" Rod**

By Burndy
Catalog # [YGHP34C2](#)

High Strength Copper Irreversible Compression Ground Rod Tap
Connector

Features

- Irreversible compression ground tap can be used as a tap connector or as a tap splice connector
- UL467 Listed
- Acceptable for direct burial in earth and concrete
- Prefilled with PENETROX™ compound and strip sealed

Application


For Direct Burial In Earth And Concrete

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Industry Standard(s)	Direct Burial
Certification - ETL	No
Standards - Industry Standards Met	• UL467 • IEEE 837 • IEEE 837 2014 Qualified
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Rebar Run Range	5 -6
Conductor - Rebar Run	• 5 • 6
Conductor - Rod Run Range	5/8 in-3/4 in
Conductor - Rod Run	• 5/8 in • 3/4 in
Conductor - Copper Str Run Range	250 kcmil-500 kcmil
Conductor - Copper Str Run	• 250 kcmil • 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil
Conductor - Copper Solid Tap Range	4 AWG-2 AWG
Conductor - Copper Solid Tap	• 4 AWG

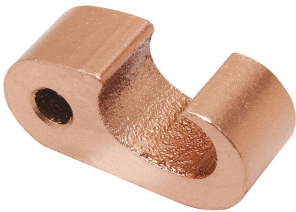

Conductor - Copper Str Tap Range	• 3 AWG • 2 AWG
Conductor - Copper Str Tap	• 4 AWG-2 AWG • 4 AWG • 3 AWG • 2 AWG

Configuration

Physical Attribute - Number of Crimps Required	1
Connector Type	Tap

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length fraction	3/4 in
Dimension - B Length inch	0.75 in

General

Trade Name	HYTAP™
Die Index	998
Oxide Inhibitor Type	Penetrox E
Prefilled Oxide Inhibitor	Y
Plated	No
Sub Brand	HYTAP
Product Type	Compression
UPC	781810220955
Type	Taps
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810220955
UPC 14 Digit GTIN	00781810220955

Logistics

Minimum Pack Quantity	1
Pallet Quantity	4625
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)



A Hubbell brand