




**YGHP58C2W2 Fig 6, Cu 1/2"-5/8" Rod Run,
#6-#2 Sol Tap**

By Burndy

Catalog # [YGHP58C2W2](#)

High Strength Copper Irreversible Compression, 1/2"-5/8" Rod Run, #6-
#2 Sol Tap

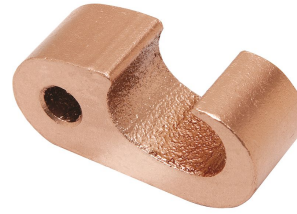

Features

- Tap A accepts a continuous run on tap conductor
- Tap B accepts a tap conductor only
- One connector style can be used for many applications reducing number of connectors needed in inventory
- High conductivity wrought copper extrusion, identical material to the conductor, minimizes resistance and voltage drop
- UL467 Listed
- Acceptable for direct burial in earth and concrete
- Prefilled with PENETROX™ compound and strip sealed

Application

For Ground Rod, Direct Burial In Earth And Concrete

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Industry Standard(s)	Direct Burial
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Rod Tap Range	1/2 in-5/8 in
Conductor - Rod Tap	• 1/2 in • 5/8 in
Conductor - Copper Solid Run Range	6 AWG-2 AWG
Conductor - Copper Solid Run	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG
Conductor - Copper Solid Tap Range	6 AWG-2 AWG
Conductor - Copper Solid Tap	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG



Configuration

Physical Attribute - Number of Crimps Required	1
Connector Type	Tap

Dimensions

Dimension - Pad Width inch	0.75 in
Package Height	0.000 in
Dimension - Height mm	48.3 mm
Dimension - Height inch	1.90 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length fraction	1-9/10 in
Dimension - Width mm	24 mm
Dimension - Width inch	0.94 in
Dimension - B Length inch	1.90 in

General

Product Family	Grounding and Bonding Connectors>"Hyground" Compression Grounding Connectors>Wire to Ground Rod
Trade Name	HYTAP™
Die Index	997
Oxide Inhibitor Type	Penetrox E
Prefilled Oxide Inhibitor	Y
Plated	No
Sub Brand	HYTAP
Product Type	Compression
UPC	781810002186
Type	Taps
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810002186
UPC 14 Digit GTIN	00781810002186

Logistics

Minimum Pack Quantity	1
Pallet Quantity	8700
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)