




YGIBW2810002N Structural Steel Compression Grounding Connector

By Burndy
Catalog # [YGIBW2810002N](#)

I-Beam Connector W/ Wide Flange Beams For Cu Cable, # 2-4/0 AWG

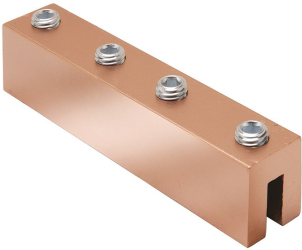

Features

- Irreversible compression ground connector allowing attachment to a structural steel standard (Angled) or wide flange (Parallel) beam
- Made of high conductivity wrought copper and prefilled with PENETROX™ E compound and strip sealed

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	• UL467 • IEEE 837
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Industry Standard(s)	• UL467 • IEEE 837
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Type	CU C Str-Size
Conductor - Copper Str Size Range	2 AWG-4/0 AWG
Conductor - Copper Str Size	• 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall	76 mm
Dimension - I Beam Thickness	1.000" -1.060"
Dimension - Length Overall	3.00 in

General

Plated	N
Trade Name	GROUNDLINK™
UPC	781810208700
Type	Taps
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810208700
UPC 14 Digit GTIN	00781810208700

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1392
Carton Quantity	6

Product Assets

[Catalog \[English\]](#)