



YH2929, Cu Compression H Tap, 250 kcmil-2 AWG Run and Tap

By Burndy

Catalog # [YH2929](#)

Copper Compression H Tap, 250 kcmil-2 AWG (Main), 250 kcmil-2 AWG (Tap), Tin Plated

Features

- Uninsulated compression H-tap connector, tin-plated
- Designs with more than one tap wire groove require installers to utilize a minimum of one Main (Run) and one Tap groove, other grooves can be left empty
- 'Third Hand' is a string provided with the H-tap connector and is used to wrap the wire while being inserted into the run and tap grooves
- H-tap connectors can be purchased separately or kitted with covers
- YH is connector sold separately without cover
- YH-WC is kitted H-tap connector and black cover
- YH-WCC is kitted H-tap connector and clear cover

Application


Wire Tap

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	BABA Compliant (All status valid till December 2026)
Industry Standard(s)	UL 486A-486B
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Material	COPPER
Conductor - Copper Flex K Tap Range	2 AWG-4/0 AWG
Conductor - Copper Flex K Tap	• 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Flex M Run Range	2 AWG-4/0 AWG

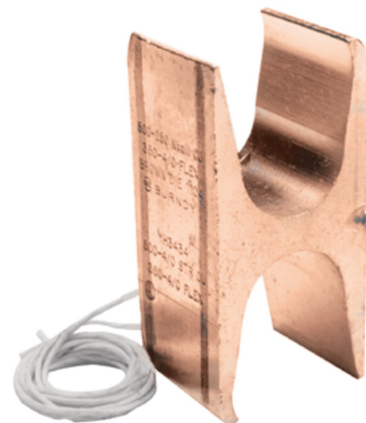

Conductor - Copper Flex M Run	• 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Flex I Tap Range	4/0 AWG-2 AWG
Conductor - Copper Flex I Tap	• 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Flex K Run Range	2 AWG-4/0 AWG
Conductor - Copper Flex K Run	• 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Flex G Run Range	2 AWG-4/0 AWG
Conductor - Copper Flex G Run	• 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Flex H Run Range	4/0 AWG
Conductor - Copper Flex H Run	4/0 AWG
Conductor - Copper Str Run Range	250 KCMIL-2 AWG
Conductor - Copper Flex G Tap Range	2 AWG-4/0 AWG
Conductor - Copper Str Run	• 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil
Conductor - Copper Flex G Tap	• 2 AWG • 1 AWG • 1/0 AWG


	2/O AWG 3/O AWG 4/O AWG
Conductor - Copper Flex M Tap Range	2 AWG-4/O AWG
Conductor - Copper Flex M Tap	2 AWG 1 AWG 1/O AWG 2/O AWG 3/O AWG 4/O AWG
Conductor - Copper Flex H Tap Range	2 AWG-4/O AWG
Conductor Type	CODE/FLEX
Conductor - Copper Flex H Tap	2 AWG 1 AWG 1/O AWG 2/O AWG 3/O AWG 4/O AWG
Conductor - Copper Flex I Run Range	2 AWG-4/O AWG
Conductor - Copper Flex I Run	4/O AWG-2 AWG
Conductor - Copper Str Tap Range	250 KCMIL-2 AWG
Conductor - Copper Str Tap	2 AWG 1 AWG 1/O 2/O AWG 3/O AWG 4/O AWG 250 kcmil

Configuration

Connector Type	H-TAP
----------------	-------

Current

Voltage Rating	35 kV
----------------	-------

 

Voltage - Maximum	35000
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height inch	1.85 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	23 mm
Dimension - Width fraction	.90 in
Dimension - Strip Length inch	1-1/16
Dimension - Width inch	1.85 in
Dimension - Length Overall inch	0.90 in

General

Trade Name	HYLUG™
Die Index	654
Plated	YES
Color Code	Purple
Sub Brand	CRIMPIT
UPC	781810013830
Type	Compression Taps
Material	Copper
Plating Type	Tin - Electro Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810013830
UPC 14 Digit GTIN	00781810013830

Logistics

Minimum Pack Quantity	1
Pallet Quantity	7200
Carton Quantity	50

Product Assets

[Catalog \[English\]](#)