


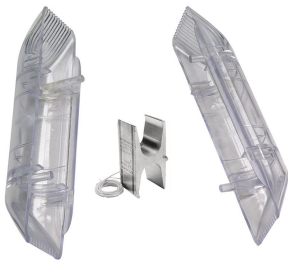

YH2929WCC, Cu Compression H Tap and Clear Cover, 250 kcmil-2 AWG Run and Tap

By Burndy
Catalog # [YH2929WCC](#)

Copper Compression H Tap, 250 kcmil-2 AWG (Main), 250 kcmil-2 AWG (Tap), Tin Plated



Features

- Uninsulated compression H-tap connector, tin-plated
- Designs with more than one tap wire groove require installers to utilize a minimum of one Main (Run) and one Tap groove, other grooves can be left empty
- 'Third Hand' is a string provided with the H-tap connector and is used to wrap the wire while being inserted into the run and tap grooves
- H-tap connectors can be purchased separately or kitted with covers
- YH is connector sold separately without cover
- YH-WC is kitted H-tap connector and black cover
- YH-WCC is kitted H-tap connector and clear cover

Application

Wire Tap

Specifications

Certification - UL Recognized	No
Buy American Compliant	Yes
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	• Buy American Act Compliant (All status valid till December 2026) • BABA Compliant (All status valid till December 2026)
Industry Standard(s)	UL 486A-486B
Certification - ETL	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Material	COPPER
Conductor - Copper Flex K Tap	• 2 • 1 • 1/0 • 2/0 • 3/0 • 4/0
Conductor - Copper Flex M Run	• 2 • 1 • 1/0

	• 2/0 • 3/0 • 4/0
Conductor - Copper Flex I Tap Range	4/0 AWG-2 AWG
Conductor - Copper Flex I Tap	• 2 • 1 • 1/0 • 2/0 • 3/0 • 4/0
Conductor - Copper Flex K Run	• 2 • 1 • 1/0 • 2/0 • 3/0 • 4/0
Conductor - Copper Flex G Run	• 2 • 1 • 1/0 • 2/0 • 3/0 • 4/0
Conductor - Copper Str Run Range	250 KCMIL-2 AWG
Conductor - Copper Str Run	• 2 • 1 • 1/0 • 2/0 • 3/0 • 4/0 • 250
Conductor - Copper Flex G Tap	• 2 • 1 • 1/0 • 2/0 • 3/0 • 4/0
Conductor - Copper Flex M Tap	• 2 • 1 • 1/0 • 2/0 • 3/0 • 4/0
Conductor Type	CODE/FLEX
Conductor - Copper Flex H Tap	• 2 • 1

	• 1/0 • 2/0 • 3/0 • 4/0
Conductor - Copper Flex I Run	4/0 AWG-2 AWG
Conductor - Copper Str Tap Range	250 KCMIL-2 AWG
Conductor - Copper Str Tap	• 2 • 1 • 1/0 • 2/0 • 3/0 • 4/0 • 250

Configuration

Connector Type	H-TAP W/CLR COVER
----------------	-------------------

Current

Voltage Rating	35 kV
Voltage - Maximum	35000

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	23 mm

Dimension - Strip Length inch	1-1/16
Dimension - Width inch	1.85 in
Dimension - Length Overall inch	0.90 in

General

Trade Name	CRIMPIT™
Die Index	654
Plated	Y
Color Code	Purple
Sub Brand	CRIMPIT
UPC	781810436424
Type	Compression Taps
Material	Copper
Plating Type	Tin - Electro Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810436424
UPC 14 Digit GTIN	00781810436424

Logistics

Minimum Pack Quantity	1
Pallet Quantity	900
Carton Quantity	10

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)

