




YH292C, Cu Compression H Tap, 250 kcmil-2 AWG Run, 2-14 AWG Tap

By Burndy

Catalog # [YH292C](#)

Copper Compression H Tap, 250 kcmil-2 AWG (Main), 2 AWG-14 AWG (Tap), Tin Plated

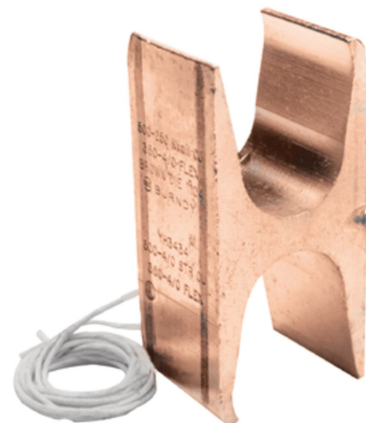

Features

- Uninsulated compression H-tap connector, tin-plated
- Designs with more than one tap wire groove require installers to utilize a minimum of one Main (Run) and one Tap groove, other grooves can be left empty
- 'Third Hand' is a string provided with the H-tap connector and is used to wrap the wire while being inserted into the run and tap grooves
- H-tap connectors can be purchased separately or kitted with covers
- YH is connector sold separately without cover
- YH-WC is kitted H-tap connector and black cover
- YH-WCC is kitted H-tap connector and clear cover

Application

Wire Tap

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Industry Standard(s)	UL 486A-486B
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Material	COPPER
Conductor - Copper Flex K Tap	• 8 • 7 • 6 • 5 • 4 • 3 • 2
Conductor - Copper Flex M Run Range	2 AWG-4/0 AWG
Conductor - Copper Flex M Run	• 2 AWG • 1 AWG • 1/0 AWG

	• 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Flex I Tap Range	2 AWG-8 AWG
Conductor - Copper Flex I Tap	• 8 • 7 • 6 • 5 • 4 • 3 • 2
Conductor - Copper Flex K Run Range	2 AWG-4/0 AWG
Conductor - Copper Flex K Run	• 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Flex G Run Range	2 AWG-4/0 AWG
Conductor - Copper Flex G Run	• 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Flex H Run Range	8 AWG-4/0 AWG
Conductor - Copper Flex H Tap	• 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Str Run Range	250 KCMIL-2 AWG
Conductor - Copper Str Run	• 2 AWG • 1 AWG • 1/0

Conductor - Copper Flex M Tap	• 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil
	• 8 • 7 • 6 • 5 • 4 • 3 • 2
Conductor - Copper Solid Tap	• 6 • 5 • 4 • 3 • 2
Conductor Type	CODE/FLEX
Conductor - Copper Flex I Run Range	2 AWG-4/0 AWG
Conductor - Copper Flex I Run	4/0 AWG-2 AWG
Conductor - Copper Str Tap Range	2 AWG-6 AWG

Configuration

Connector Type	H-TAP
----------------	-------

Current

Voltage Rating	35 kV
Voltage - Maximum	35000

Dimensions

Package Height	0.000 in
Dimension - Height inch	1.52 in
Package Weight	0.000 lb.

Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall	23 mm
mm	
Dimension - Width fraction	.90 in
Dimension - Strip Length inch	1-1/16
Dimension - Width inch	1.52 in
Dimension - Length Overall	0.90 in
inch	

General

Trade Name	CRIMPIT™
Die Index	654
Plated	Y
Color Code	Purple
Sub Brand	CRIMPIT
UPC	781810013878
Type	Compression Taps
Material	Copper
Plating Type	Tin - Electro Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810013878
UPC 14 Digit GTIN	00781810013878

Logistics

Minimum Pack Quantity	1
Pallet Quantity	8640
Carton Quantity	60

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)

