


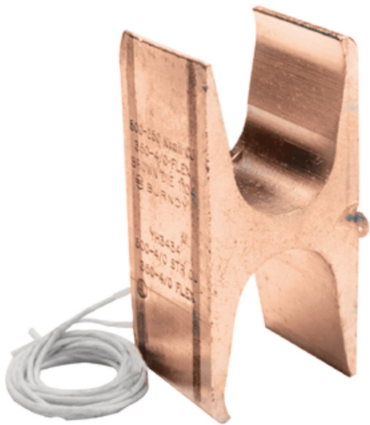

YH298C, Compression H-Tap

By Burndy
Catalog # [YH298C](#)

Copper Compression H Tap, 250 kcmil-2 AWG (Main), 8 AWG-14 AWG (Tap), Tin Plated



Features

- Uninsulated compression H-tap connector, tin-plated
- Designs with more than one tap wire groove require installers to utilize a minimum of one Main (Run) and one Tap groove, other grooves can be left empty
- 'Third Hand' is a string provided with the H-tap connector and is used to wrap the wire while being inserted into the run and tap grooves
- H-tap connectors can be purchased separately or kitted with covers
- YH is connector sold separately without cover
- YH-WC is kitted H-tap connector and black cover
- YH-WCC is kitted H-tap connector and clear cover

Application

Wire Tap

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
Industry Standard(s)	UL 486A-486B
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Material	COPPER
Conductor - Copper Flex K Tap Range	8 AWG
Conductor - Copper Flex K Tap	• 14 • 8
Conductor - Copper Flex M Run	• 2 • 1 • 1/0 • 2/0 • 3/0 • 4/0
Conductor - Copper Flex I Tap Range	8 AWG-14 AWG

Conductor - Copper Flex I Tap	• 14 • 8
Conductor - Copper Flex K Run	• 2 • 1 • 1/0 • 2/0 • 3/0 • 4/0
Conductor - Copper Flex G Run Range	2-4/0
Conductor - Copper Flex G Run	• 2 • 1 • 1/0 • 2/0 • 3/0 • 4/0
Conductor - Copper Flex H Run Range	8 AWG-4/0 AWG
Conductor - Copper Flex H Run	• 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Str Run Range	250 KCMIL-2 AWG
Conductor - Copper Flex G Tap Range	8 AWG-14 AWG
Conductor - Copper Str Run	• 2 • 1 • 1/0 • 2/0 • 3/0 • 4/0 • 250
Conductor - Copper Flex G Tap	• 14 • 8
Conductor - Copper Flex M Tap	• 14 • 8
Conductor - Copper Flex H Tap Range	8 AWG-14 AWG

Conductor Type	CODE/FLEX	Dimension - Width inch	1.52 in
Conductor - Copper Flex H Tap	• 14 • 8	Dimension - Length Overall inch	0.90 in
Conductor - Copper Flex I Run	4/0 AWG-2 AWG		
Conductor - Copper Str Tap Range	8 AWG-14 AWG	General	
Conductor - Copper Str Tap	• 14 • 12 • 10 • 9 • 8	Trade Name	CRIMPIT™
		Die Index	654
		Plated	Y
		Color Code	Purple
		Sub Brand	CRIMPIT
		UPC	781810013915
		Type	Compression Taps
		Material	Copper
		Plating Type	Tin - Electro Plated
		Finish Type	Tin-Plated
		UPC 12 Digit	781810013915
		UPC 14 Digit GTIN	00781810013915
Configuration		Logistics	
Connector Type	H-TAP	Minimum Pack Quantity	1
		Pallet Quantity	7200
		Carton Quantity	50
Current		Operational	
Voltage Rating	35 kV	Temperature Rating	194
Voltage - Maximum	35000		
Dimensions		Product Assets	
Package Height	0.000 in	Catalog [English]	
Dimension - Height inch	1.52 in		
Package Weight	0.000 lb.		
Package Length	0.000 in		
Package Width	0.000 in		
Dimension - L Length Overall mm	23 mm		
Dimension - Width fraction	.90 in		
Dimension - Strip Length inch	1-1/16		

