




YH3939, Compression H-Tap

By Burndy
Catalog # [YH3939](#)

Copper Compression H Tap, 750 KCMIL-500 KCMIL (Main), 750 KCMIL-350 KCMIL (Tap), Tin Plated

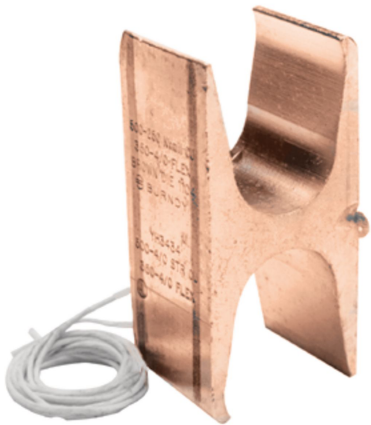

Features

- Uninsulated compression H-tap connector, tin-plated
- Designs with more than one tap wire groove require installers to utilize a minimum of one Main (Run) and one Tap groove, other grooves can be left empty
- 'Third Hand' is a string provided with the H-tap connector and is used to wrap the wire while being inserted into the run and tap grooves
- H-tap connectors can be purchased separately or kitted with covers
- YH is connector sold separately without cover
- YH-WC is kitted H-tap connector and black cover
- YH-WCC is kitted H-tap connector and clear cover

Application

Wire Tap

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL 486A-486B
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Material	COPPER
Conductor - Copper Flex K Tap	• 350 • 400 • 450 • 500
Conductor - Copper Flex M Run	• 450 • 500
Conductor - Copper Flex I Tap	550 KCMIL-350 KCMIL
Conductor - Copper Flex I Tap Range	
Conductor - Copper Flex I Tap	• 350 • 400 • 450


Conductor - Copper Flex K Run	• 500 • 450 • 500
Conductor - Copper Flex G Run Range	450-500
Conductor - Copper Flex G Run	• 450 • 500
Conductor - Copper Flex H Run Range	500 kcmil
Conductor - Copper Flex H Run	500 kcmil
Conductor - Copper Str Run Range	750 KCMIL-500 KCMIL
Conductor - Copper Flex G Tap Range	350-500
Conductor - Copper Str Run	• 500 • 550 • 600 • 700 • 750
Conductor - Copper Flex G Tap	• 350 • 400 • 450 • 500
Conductor - Copper Flex M Tap	• 350 • 400 • 450 • 500
Conductor - Copper Flex H Tap Range	350-500
Conductor Type	CODE/FLEX
Conductor - Copper Flex H Tap	• 350 • 400 • 450 • 500
Conductor - Copper Flex I Run	550 KCMIL-450 KCMIL
Conductor - Copper Str Tap Range	750 KCMIL-350 KCMIL
Conductor - Copper Str Tap	• 350 • 400 • 450 • 500 • 550 • 600 • 700

Configuration

Connector Type	H-TAP	Die Index	KR
Current		Plated	Y
		Color Code	Yellow
Voltage Rating	35 kV	Sub Brand	CRIMPIT
Voltage - Maximum	35000	UPC	781810013847
Dimensions		Type	Compression Taps
		Material	Copper
		Plating Type	Tin - Electro Plated
		Finish Type	Tin-Plated
		UPC 12 Digit	781810013847
		UPC 14 Digit GTIN	00781810013847
		Logistics	
Package Height	0.000 in	Minimum Pack Quantity	1
Dimension - Height inch	2.97 in	Pallet Quantity	2880
Package Weight	0.000 lb.	Carton Quantity	30
Package Length	0.000 in	Operational	
Package Width	0.000 in		
Dimension - L Length Overall	32 mm		
mm			
Dimension - Width fraction	1.50 in	Product Assets	
Dimension - Strip Length inch	1-3/8		
Dimension - Width inch	2.97 in		
Dimension - Length Overall	1.25 in		
inch		Temperature Rating	194

General

 Trade NameCRIMPIT™



[Catalog \[English\]](#)