


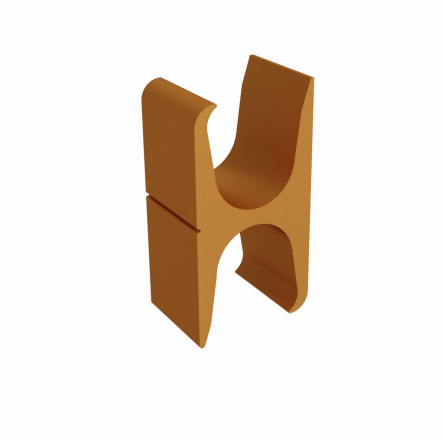

YH4434WC, Compression H-Tap

By Burndy
Catalog # [YH4434WC](#)

Copper Compression H Tap, 1000 KCMIL-750 KCMIL (Main), 500 KCMIL-350 KCMIL (Tap), Tin Plated



Features

- Uninsulated compression H-tap connector, tin-plated
- Designs with more than one tap wire groove require installers to utilize a minimum of one Main (Run) and one Tap groove, other grooves can be left empty
- 'Third Hand' is a string provided with the H-tap connector and is used to wrap the wire while being inserted into the run and tap grooves
- H-tap connectors can be purchased separately or kitted with covers
- YH is connector sold separately without cover
- YH-WC is kitted H-tap connector and black cover
- YH-WCC is kitted H-tap connector and clear cover

Application

Wire Tap

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	NC
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Flex G Run	• 500 • 600 • 700
Conductor - Copper Str Run Range	1000 KCMIL-750 KCMIL
Conductor - Copper Str Run	• 700 • 750 • 800 • 850 • 900 • 1000
Conductor - Copper Flex G Tap	350
Conductor - Copper Flex M Tap	350
Conductor - Material	COPPER
Conductor - Copper Flex K Tap	350
Conductor - Copper Flex M Run	• 500 • 600

Conductor Type	• 700
Conductor - Copper Flex H Tap	CODE/FLEX 350
Conductor - Copper Flex I Run	750 KCMIL-500 KCMIL
Conductor - Copper Str Tap Range	500 KCMIL-350 KCMIL
Conductor - Copper Str Tap	• 350 • 400 • 450 • 500
Conductor - Copper Flex I Tap Range	350 KCMIL
Conductor - Copper Flex I Tap	350
Conductor - Copper Flex K Run	• 500 • 600 • 700

Configuration

Connector Type	H-TAP W/BLK COVER
----------------	-------------------

Current

Voltage Rating	35 kV
Voltage - Maximum	35000

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Dimension - Width inch	3.50 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	25 mm
Dimension - Length Overall inch	1.00 in
Dimension - Strip Length inch	1-3/8

General

Plated	Y
Color Code	Yellow
Trade Name	CRIMPIT™
Die Index	KR
UPC	781810418925
Type	Compression Taps
Material	Copper
Plating Type	Tin - Electro Plated

Finish Type	Tin-Plated	Carton Quantity	5
UPC 12 Digit	781810418925		
UPC 14 Digit GTIN	00781810418925		
		Operational	
		Temperature Rating	194
		Product Assets	
		Catalog [English]	

