


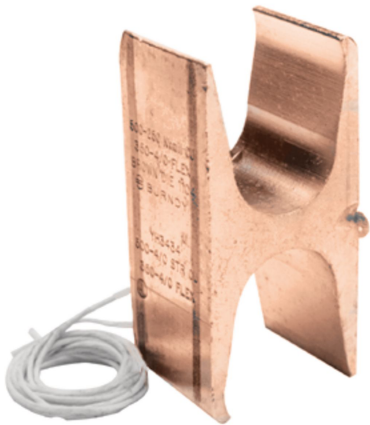

YH4444, Compression H-Tap

By Burndy
Catalog # [YH4444](#)

Copper Compression H Tap, 1000 KCMIL-750 KCMIL (Main), 1000 KCMIL-750 KCMIL (Tap), Tin Plated



Features

- Uninsulated compression H-tap connector, tin-plated
- Designs with more than one tap wire groove require installers to utilize a minimum of one Main (Run) and one Tap groove, other grooves can be left empty
- 'Third Hand' is a string provided with the H-tap connector and is used to wrap the wire while being inserted into the run and tap grooves
- H-tap connectors can be purchased separately or kitted with covers
- YH is connector sold separately without cover
- YH-WC is kitted H-tap connector and black cover
- YH-WCC is kitted H-tap connector and clear cover

Application

Wire Tap

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Material	COPPER
Conductor - Copper Flex K Tap Range	500 kcmil-700 kcmil
Conductor - Copper Flex K Tap	• 500 kcmil • 600 kcmil • 700 kcmil
Conductor - Copper Flex M Run Range	500 kcmil-700 kcmil
Conductor - Copper Flex M Run	• 500 kcmil • 600 kcmil • 700 kcmil
Conductor - Copper Flex I Tap Range	750 KCMIL-350 KCMIL
Conductor - Copper Flex I Tap	• 500 kcmil • 550 kcmil

	• 600 kcmil • 700 kcmil
Conductor - Copper Flex K Run Range	500 kcmil-700 kcmil
Conductor - Copper Flex K Run	• 500 kcmil • 600 kcmil • 700 kcmil
Conductor - Copper Flex G Run Range	500 kcmil-700 kcmil
Conductor - Copper Flex G Run	• 500 kcmil • 600 kcmil • 700 kcmil
Conductor - Copper Flex H Run Range	700 kcmil
Conductor - Copper Flex H Run	700 kcmil
Conductor - Copper Str Run Range	1000 KCMIL-750 KCMIL
Conductor - Copper Flex G Tap Range	500 kcmil-700 kcmil
Conductor - Copper Str Run	• 700 kcmil • 750 kcmil • 800 kcmil • 850 kcmil • 900 kcmil • 1000 kcmil
Conductor - Copper Flex G Tap	• 500 kcmil • 600 kcmil • 700 kcmil
Conductor - Copper Flex M Tap Range	500 kcmil-700 kcmil
Conductor - Copper Flex M Tap	• 500 kcmil • 600 kcmil • 700 kcmil
Conductor - Copper Flex H Tap Range	500 kcmil-700 kcmil
Conductor Type	CODE/FLEX
Conductor - Copper Flex H Tap	• 500 kcmil • 600 kcmil • 700 kcmil
Conductor - Copper Flex I Run Range	500 kcmil-700 kcmil
Conductor - Copper Flex I Run	750 KCMIL-500 KCMIL
Conductor - Copper Str Tap Range	1000 KCMIL-750 KCMIL
Conductor - Copper Str Tap	• 750 kcmil • 800 kcmil • 850 kcmil

- 900 kcmil
- 1000 kcmil

Configuration

Connector TypeH-TAP

Current

Voltage Rating35 kV
Voltage - Maximum35000

Dimensions

Package Height0.000 in
Dimension - Height inch3.38 in
Package Weight0.000 lb.
Package Length0.000 in
Package Width0.000 in
Dimension - L Length Overall610 mm
mm
Dimension - Width fraction1.70 in
Dimension - Strip Length inch1-1/8
Dimension - Width inch3.38 in
Dimension - Length Overall1 in
inch

General

Trade NameCRIMPIT™
Die Index1102
PlatedY
Color CodeWhite
UPC781810013854
TypeCompression Taps
MaterialCopper
Plating TypeTin - Electro Plated
Finish TypeTin-Plated
UPC 12 Digit781810013854
UPC 14 Digit GTIN00781810013854

Logistics

Minimum Pack Quantity1
Pallet Quantity2250
Carton Quantity50

Operational

Temperature Rating194

Product Assets

[Catalog \[English\]](#)



A Hubbell brand