



YH6C6C, Copper Compression H-Tap, Run: #6-10 AWG, Tap: #6-14 AWG, Tin Plated

By Burndy
Catalog # [YH6C6C](#)

Copper Compression H Tap, 6 AWG-10 AWG (Main), 6 AWG-14 AWG (Tap), Tin Plated

Features

- Uninsulated compression H-tap connector, tin-plated
- Designs with more than one tap wire groove require installers to utilize a minimum of one Main (Run) and one Tap groove, other grooves can be left empty
- 'Third Hand' is a string provided with the H-tap connector and is used to wrap the wire while being inserted into the run and tap grooves
- H-tap connectors can be purchased separately or kitted with covers
- YH is connector sold separately without cover
- YH-WC is kitted H-tap connector and black cover
- YH-WCC is kitted H-tap connector and clear cover

Application


Wire Tap

Specifications

Certification - UL Recognized	No
Buy American Compliant	Yes
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	• Buy American Act Compliant (All status valid till December 2026) • BABA Compliant (All status valid till December 2026)
Industry Standard(s)	UL 486A-486B
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Material	COPPER
Conductor - Copper Flex K Tap	• 14 • 8 • 7 • 6
Conductor - Copper Flex M Run	• 8 • 7 • 6

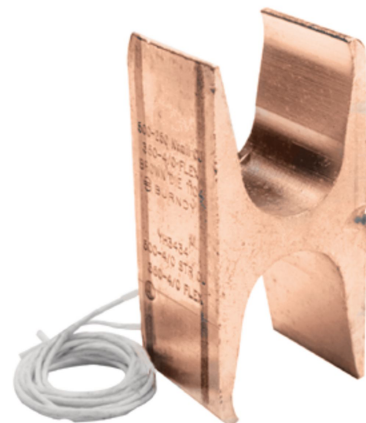

Conductor - Copper Flex I Tap Range	6 AWG-14 AWG
Conductor - Copper Flex I Tap	• 14 • 8 • 7 • 6
Conductor - Copper Flex K Run	• 8 • 7 • 6
Conductor - Copper Flex G Run Range	8-6
Conductor - Copper Flex G Run	• 8 • 7 • 6
Conductor - Copper Flex H Run Range	6 AWG
Conductor - Copper Flex H Run	6 AWG
Conductor - Copper Str Run Range	6 AWG-10 AWG
Conductor - Copper Flex G Tap Range	14-6
Conductor - Copper Str Run	• 10 • 9 • 8 • 7 • 6
Conductor - Copper Flex G Tap	• 14 • 8 • 7 • 6
Conductor - Copper Flex M Tap	• 14 • 8 • 7 • 6
Conductor - Copper Flex H Tap Range	14-6
Conductor Type	CODE/FLEX
Conductor - Copper Flex H Tap	• 14 • 8 • 7 • 6
Conductor - Copper Flex I Run	6 AWG-10 AWG
Conductor - Copper Str Tap Range	6 AWG-14 AWG
Conductor - Copper Str Tap	• 14 • 12 • 10

- 9
- 8
- 7
- 6

Configuration

Connector TypeH-TAP

Current

Voltage Rating35 kV
Voltage - Maximum35000

Dimensions

Package Height0.000 in
Dimension - Height inch0.81 in
Package Weight0.000 lb.
Package Length0.000 in
Package Width0.000 in
Dimension - L Length Overall15 mm
mm
Dimension - Width fraction.39 in
Dimension - Strip Length inch3/4
Dimension - Width inch0.81 in
Dimension - Length Overall0.60 in
inch

General

Trade NameCRIMPIT™
Die IndexBG
PlatedY
Color CodeOrange
Sub BrandCRIMPIT
UPC781810042373
TypeCompression Taps
MaterialCopper
Plating TypeTin - Electro Plated
Finish TypeTin-Plated
UPC 12 Digit781810042373
UPC 14 Digit GTIN00781810042373

Logistics

Minimum Pack Quantity1
Pallet Quantity13500
Carton Quantity150

Operational

Temperature Rating194

Product Assets

[Catalog \[English\]](#)

