




YH8C8C, Compression H-Tap

By Burndy
Catalog # [YH8C8C](#)

Copper Compression H Tap, 8 AWG-14 AWG (Main), 8 AWG-14 AWG (Tap), Tin Plated

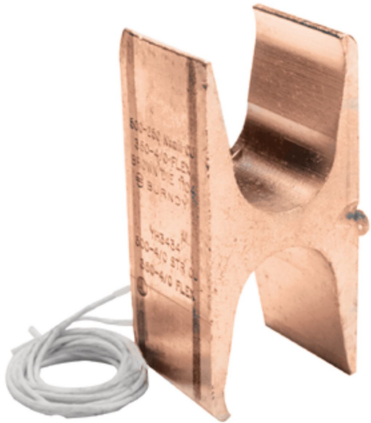

Features

- Uninsulated compression H-tap connector, tin-plated
- Designs with more than one tap wire groove require installers to utilize a minimum of one Main (Run) and one Tap groove, other grooves can be left empty
- 'Third Hand' is a string provided with the H-tap connector and is used to wrap the wire while being inserted into the run and tap grooves
- H-tap connectors can be purchased separately or kitted with covers
- YH is connector sold separately without cover
- YH-WC is kitted H-tap connector and black cover
- YH-WCC is kitted H-tap connector and clear cover

Application

Wire Tap

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Material	COPPER
Conductor - Copper Flex K Tap	• 14 • 8
Conductor - Copper Flex M Run	• 14 • 8
Conductor - Copper Flex I Tap	8 AWG-14 AWG
Conductor - Copper Flex I Tap Range	
Conductor - Copper Flex I Tap	• 14 • 8
Conductor - Copper Flex K Run	• 14 • 8
Conductor - Copper Flex G Run	14-8
Conductor - Copper Flex G Run Range	
Conductor - Copper Flex G Run	• 14 • 8

Conductor - Copper Flex H Run	8 AWG
Conductor - Copper Flex H Run Range	
Conductor - Copper Flex H Run	8 AWG
Conductor - Copper Str Run	8 AWG-14 AWG
Conductor - Copper Str Run Range	
Conductor - Copper Flex G Tap	14-8
Conductor - Copper Flex G Tap Range	
Conductor - Copper Str Run	• 14 • 12 • 10 • 9 • 8
Conductor - Copper Flex G Tap	• 14 • 8
Conductor - Copper Flex M Tap	• 14 • 8
Conductor - Copper Flex H Tap	14-8
Conductor - Copper Flex H Tap Range	
Conductor Type	CODE/FLEX
Conductor - Copper Flex H Tap	• 14 • 8
Conductor - Copper Flex I Run	8 AWG-14 AWG
Conductor - Copper Str Tap	8 AWG-14 AWG
Conductor - Copper Str Tap Range	
Conductor - Copper Str Tap	• 14 • 12 • 10 • 9 • 8

Configuration

Connector Type	H-TAP
----------------	-------

Current

Voltage Rating	35 kV
Voltage - Maximum	35000

Dimensions

Package Height	0.000 in
Dimension - Height inch	0.63 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	15 mm
Dimension - Width fraction	.40 in

Dimension - Strip Length inch	3/4	Finish Type	Tin-Plated
Dimension - Width inch	0.63 in	UPC 12 Digit	781810013908
Dimension - Length Overall inch	0.60 in	UPC 14 Digit GTIN	00781810013908

General

Trade Name	CRIMPIT™
Die Index	11
Plated	Y
Color Code	Green
UPC	781810013908
Type	Compression Taps
Material	Copper
Plating Type	Tin - Electro Plated

Logistics

Minimum Pack Quantity	1
Pallet Quantity	9900
Carton Quantity	300

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)



A Hubbell brand