


YHD7, Line Tap Connector, AL-CU, AL-AL

By Burndy
Catalog # [YHD7](#)

Compression Line Tap Connector for Aluminum to Copper and Aluminum to Aluminum applications, 1.40 H, 2.52 L, .84 W

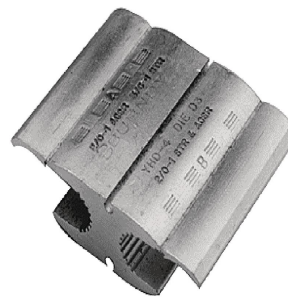

Features

- LOKTAP™ compression connectors are high quality, range-taking devices accommodating many combinations of conductor
- LOKTAP™ connectors feature a C groove on both sides of the connector for use in street lighting applications

Application

For Accommodate Combinations Of Aluminum To Copper, And Aluminum To Aluminum Conductors

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - ACSR Cmpt Run Range	3/0 AWG-266.8 kcmil
Conductor - ACSR Cmpt Run	• 3/0 AWG • 4/0 AWG • 266.8 kcmil
Conductor - AL Str Run Range	250 kcmil-300 kcmil
Conductor - AL Str Run	• 250 kcmil • 300 kcmil
Conductor - AL Str Tap Range	3/0 AWG-4/0 AWG
Conductor - AL Str Tap	• 3/0 AWG • 4/0 AWG
Conductor - ACSR Cmpt Tap Range	3/0 AWG-266.8 kcmil
Conductor - ACSR Cmpt Tap	• 3/0 AWG • 4/0 AWG • 266.8 kcmil
Conductor - ACSR Str Run Range	3/0 (6/1) Pigeon AWG-4/0 (6/1) Penquin AWG
Conductor - ACSR Str Run	• 3/0 (6/1) Pigeon AWG • 4/0 (6/1) Penquin AWG
Conductor - ACSR Str Tap Range	3/0 (6/1) Pigeon AWG-4/0 (6/1) Penquin AWG
Conductor - ACSR Str Tap	• 3/0 (6/1) Pigeon AWG • 4/0 (6/1) Penquin AWG

Conductor - Copper Str Run Range	250 kcmil-300 kcmil
Conductor - Copper Str Run	3/0 AWG, 4/0 AWG
Conductor - Copper Solid Run Range	250 kcmil-300 kcmil
Conductor - Copper Solid Run	• 250 kcmil • 300 kcmil
Conductor - Copper Solid Tap Range	250 kcmil - 300 kcmil
Conductor - Copper Solid Tap	250 kcmil, 300 kcmil
Conductor - Copper Str Tap Range	3/0 AWG-4/0 AWG
Conductor - Copper Str Tap	• 3/0 AWG • 4/0 AWG

Dimensions

Package Height	2.750 in
Dimension - Height mm	35.6 mm
Dimension - Height inch	1.40 in
Dimension - Height fraction	1-2/5 in
Package Weight	4.230 lb.
Package Length	13.400 in
Package Width	4.750 in
Dimension - L Length Overall mm	64 mm
Dimension - Width fraction	21/25 in
Dimension - Width mm	21 mm
Dimension - Width inch	0.84 in
Dimension - Length Overall inch	2.52 in

General

Product Family	Utility Overhead & Underground Distribution>Compression Tap Connectors>H-Taps
Trade Name	LOKTAP™
Die Index	D3
Prefilled Oxide Inhibitor	Y
Plated	No
Sub Brand	LOKTAP
Product Type	Compression
UPC	781810139165
Type	YHN
Material	Aluminum
Plating Type	Unplated
UPC 14 Digit GTIN	00781810139165

Logistics

Minimum Pack Quantity	25
Pallet Quantity	3200

[Catalog \[English\]](#)



A Hubbell brand