


YHR750, Line Tap for Cu, AL, ACSR, Compact

By Burndy
Catalog # [YHR750](#)

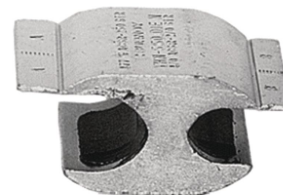

Compression Line Tap for Copper, AL or ACSR and Compact Conductors, groove A(Run) ACSR:300 - 556 (18/1)

Features

- Wide range, universal and reversible Figure H-Shaped aluminum connector
- Conductors are separated by the shape of the connector
- Bendable tabs secure both run and tap conductors freeing the installer to work with the installation tool
- Massive aluminum design miniizes corrosion due to galvanic corrosion
- Prefilled with PENETROX Joint Compound and individually packaged

Application

For Copper, Aluminum Or ACSR And Compact Conductors

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - ACSR Cmpt Run Range	397.5 (18/1) Chickadee kcmil-636 kcmil
Conductor - ACSR Cmpt Run	• 397.5 (18/1) Chickadee kcmil • 397.5 (24/7) Brant kcmil • 397.5 (26/7) Ibis kcmil • 397.5 (30/7) Larkspur kcmil • 477.0 (18/1) Pelican kcmil • 477.0 (24/7) Flicker kcmil • 477.0 (26/7) Hawk kcmil • 477. (30/7) Hen kcmil • 500.0 (30/7) Heron kcmil • 556.5 (24/7) Parakeet kcmil • 636 kcmil
Conductor - AL Str Run Range	336 kcmil-600 kcmil
Conductor - AL Str Run	• 336 kcmil • 350 kcmil • 397 kcmil • 400 kcmil • 450 kcmil • 477 kcmil • 500 kcmil

	• 550 kcmil • 556 kcmil • 600 kcmil
Conductor - AL Str Tap Range	300 kcmil-600 kcmil
Conductor - AL Str Tap	• 300 kcmil • 336 kcmil • 350 kcmil • 397 kcmil • 400 kcmil • 450 kcmil • 477 kcmil • 500 kcmil • 550 kcmil • 556 kcmil • 600 kcmil
Conductor - ACSR Cmpt Tap Range	397.5 (18/1) Chickadee kcmil-636 kcmil
Conductor - ACSR Cmpt Tap	• 397.5 (18/1) Chickadee kcmil • 397.5 (24/7) Brant kcmil • 397.5 (26/7) Ibis kcmil • 397.5 (30/7) Larkspur kcmil • 477.0 (18/1) Pelican kcmil • 477.0 (24/7) Flicker kcmil • 477.0 (26/7) Hawk kcmil • 477. (30/7) Hen kcmil • 500.0 (30/7) Heron kcmil • 556.5 (24/7) Parakeet kcmil • 636 kcmil
Conductor - ACSR Str Run Range	300.0 (26/7) Ostrich kcmil-556.5 (18/1) kcmil
Conductor - ACSR Str Run	• 300.0 (26/7) Ostrich kcmil • 336.4 (18/1) Merlin kcmil • 336.4 (26/7) Linnet kcmil • 336.4 (30/7) Oriole kcmil • 397.5 (18/1) Chickadee kcmil • 397.5 (24/7) Brant kcmil • 397.5 (26/7) Ibis kcmil • 397.5 (30/7) Larkspur kcmil • 477.0 (18/1) Pelican kcmil • 477.0 (24/7) Flicker kcmil • 477.0 (26/7) Hawk kcmil • 477. (30/7) Hen kcmil • 500.0 (30/7) Heron kcmil • 556.5 (18/1) kcmil
Conductor - ACSR Str Tap Range	300.0 (26/7) Ostrich kcmil-556.5 (18/1) kcmil
Conductor - ACSR Str Tap	• 300.0 (26/7) Ostrich kcmil

- Conductor - Copper Str Run Range

Conductor - Copper Str Run

Conductor - Copper Str Tap Range

Conductor - Copper Str Tap
- 336.4 (18/1) Merlin kcmil

• 336.4 (26/7) Linnet kcmil

• 336.4 (30/7) Oriole kcmil

• 397.5 (18/1) Chickadee kcmil

• 397.5 (24/7) Brant kcmil

• 397.5 (26/7) Ibis kcmil

• 397.5 (30/7) Larkspur kcmil

• 477.0 (18/1) Pelican kcmil

• 477.0 (24/7) Flicker kcmil

• 477.0 (26/7) Hawk kcmil

• 477. (30/7) Hen kcmil

• 500.0 (30/7) Heron kcmil

• 556.5 (18/1) kcmil

350 kcmil-600 kcmil

• 350 kcmil

• 400 kcmil

• 450 kcmil

• 500 kcmil

• 550 kcmil

• 600 kcmil

350 kcmil-600 kcmil

• 350 kcmil

• 400 kcmil

• 450 kcmil

• 500 kcmil

• 550 kcmil

• 600 kcmil

Dimensions

Package Height	0.000 in
Dimension - Height mm	77.2 mm
Dimension - Height inch	3.04 in
Dimension - Height fraction	3-1/25 in



Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	117 mm
Dimension - Width fraction	1-37/50 in
Dimension - Width mm	44 mm
Dimension - Width inch	1.74 in
Dimension - Length Overall inch	4.62 in

General

Product Family	Utility Overhead & Underground Distribution>Compression Tap Connectors>H-Taps
Trade Name	HYCRIMP™
Die Index	KR
Prefilled Oxide Inhibitor	Y
Plated	No
Sub Brand	HYCRIMP
Product Type	Compression
UPC	781810139707
Type	YHR
Material	Aluminum
Plating Type	Unplated
UPC 14 Digit GTIN	00781810139707

Logistics

Minimum Pack Quantity	10
Pallet Quantity	440
Carton Quantity	10

Product Assets

[Catalog \[English\]](#)