



YHR800, Line Tap for Cu, AL, ACSR, Compact

By Burndy
Catalog # [YHR800](#)

Compression Line Tap for Copper, AL or ACSR and Compact Conductors, wire diameter range, groove A(Run):0.879-1.108

Features

- Wide range, universal and reversible Figure H-Shaped aluminum connector
- Conductors are separated by the shape of the connector
- Bendable tabs secure both run and tap conductors freeing the installer to work with the installation tool
- Massive aluminum design miniizes corrosion due to galvanic corrosion
- Prefilled with PENETROX Joint Compound and individually packaged

Application


For Copper, Aluminum Or ACSR And Compact Conductors

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - ACSR Cmpt Run Range	795 - 954 kcmil
Conductor - ACSR Cmpt Run	795 - 954 kcmil
Conductor - AL Str Run Range	600 kcmil-900 kcmil
Conductor - AL Str Run	• 600 kcmil • 636 kcmil • 650 kcmil • 700 kcmil • 715 kcmil • 750 kcmil • 795 kcmil • 800 kcmil • 874 kcmil • 900 kcmil
Conductor - AL Str Tap Range	2/0 AWG-350 kcmil
Conductor - AL Str Tap	• 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil

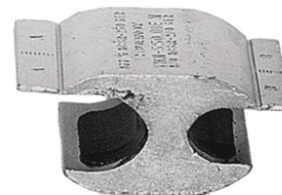

Conductor - ACSR Cmpt Tap Range	• 336 kcmil • 350 kcmil 795 - 954 kcmil
Conductor - ACSR Cmpt Tap	795 - 954 kcmil
Conductor - ACSR Str Run Range	556.5 (24/7) Parakeet kcmil-795 (26/7) Drake kcmil
Conductor - ACSR Str Run	• 556.5 (24/7) Parakeet kcmil • 556.5 (26/7) Dove kcmil • 556.5 (30/7) Eagle kcmil • 605 (24/7) Peacock kcmil • 605 (26/7) Squab kcmil • 605 (30/19) Teal kcmil • 636 (24/7) Rook kcmil • 636 (26/7) Grosbeak kcmil • 636 (30/19) Egret kcmil • 666.6 (24/7) Flamingo kcmil • 715.5 (54/7) Crow kcmil • 715.5 (24/7) Stilt kcmil • 715.5 (26/7) Starling kcmil • 715.5 (30/19) Redwing kcmil • 795 (54/7) Condor kcmil • 795 (26/7) Drake kcmil
Conductor - ACSR Str Tap Range	1/0 (6/1) Raven AWG-336.4 (18/1) Merlin kcmil
Conductor - ACSR Str Tap	• 1/0 (6/1) Raven AWG • 2/0 (6/1) Quail AWG • 3/0 (6/1) Pigeon AWG • 4/0 (6/1) Penquin AWG • 80 (8/1) Grouse kcmil • 101.8 (12/7) Petrel kcmil • 110.8 (12/7) Minorca kcmil • 134.6 (12/7) Leghorn kcmil • 159 (12/7) Guinea kcmil • 176.9 (12/7) Dotterel kcmil • 190.8 (12/7) Dorking kcmil • 211.3 (12/7) Cochin kcmil • 203.2 (16/9) Brahma kcmil • 266.8 (18/1) Waxwing kcmil • 266.8 (26/7) Owl kcmil • 266.8 (26/7) Partridge kcmil • 300.0 (26/7) Ostrich kcmil • 336.4 (18/1) Merlin kcmil
Conductor - Copper Str Run Range	600 kcmil-900 kcmil
Conductor - Copper Str Run	• 600 kcmil • 700 kcmil • 750 kcmil

	• 800 kcmil • 850 kcmil • 900 kcmil
Conductor - Copper Solid Tap Range	3/0 AWG-350 kcmil
Conductor - Copper Solid Tap	• 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil
Conductor - Copper Str Tap Range	2/0 AWG-350 kcmil
Conductor - Copper Str Tap	• 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil

Dimensions

Package Height	0.000 in
Dimension - Height mm	77.5 mm
Dimension - Height inch	3.05 in
Dimension - Height fraction	3-1/20 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	89 mm
Dimension - Width fraction	1-37/50 in

Dimension - Width mm	44 mm
Dimension - Width inch	1.74 in
Dimension - Length Overall inch	3.50 in

General

Product Family	Utility Overhead & Underground Distribution>Compression Tap Connectors>H-Taps
Trade Name	HYCRIMP™
Die Index	KR
Prefilled Oxide Inhibitor	Y
Plated	No
Sub Brand	HYCRIMP
Product Type	Compression
UPC	781810139752
Type	YHR
Material	Aluminum
Plating Type	Unplated
UPC 14 Digit GTIN	00781810139752

Logistics

Minimum Pack Quantity	10
Pallet Quantity	660
Carton Quantity	10

Product Assets

[Catalog \[English\]](#)

