



YHR900, Line Tap for Cu, AL, ACSR, Compact

By Burndy
Catalog # [YHR900](#)

Compression Line Tap for Copper, AL or ACSR and Compact Conductors, groove A(Run) ACSR:556.5 (18/1) - 795 (26/7)

Features

- Wide range, universal and reversible Figure H-Shaped aluminum connector
- Conductors are separated by the shape of the connector
- Bendable tabs secure both run and tap conductors freeing the installer to work with the installation tool
- Massive aluminum design miniizes corrosion due to galvanic corrosion
- Prefilled with PENETROX Joint Compound and individually packaged

Application


For Copper, Aluminum Or ACSR And Compact Conductors

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - ACSR Cmpt Run Range	795 - 954
Conductor - ACSR Cmpt Run	795 - 954
Conductor - AL Str Run Range	600 kcmil-900 kcmil
Conductor - AL Str Run	• 600 kcmil • 636 kcmil • 650 kcmil • 700 kcmil • 715 kcmil • 750 kcmil • 795 kcmil • 800 kcmil • 874 kcmil • 900 kcmil
Conductor - AL Str Tap Range	600 kcmil-900 kcmil
Conductor - AL Str Tap	• 600 kcmil • 636 kcmil • 650 kcmil • 700 kcmil • 715 kcmil • 750 kcmil

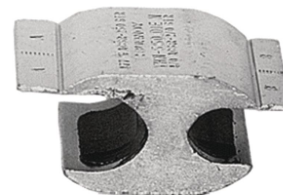

	• 795 kcmil • 800 kcmil • 874 kcmil • 900 kcmil
Conductor - ACSR Cmpt Tap Range	795 - 954
Conductor - ACSR Cmpt Tap	795 - 954
Conductor - ACSR Str Run Range	556.5 (24/7) Parakeet kcmil-795 (26/7) Drake kcmil
Conductor - ACSR Str Run	• 556.5 (24/7) Parakeet kcmil • 556.5 (26/7) Dove kcmil • 556.5 (30/7) Eagle kcmil • 605 (24/7) Peacock kcmil • 605 (26/7) Squab kcmil • 605 (30/19) Teal kcmil • 636 (24/7) Rook kcmil • 636 (26/7) Grosbeak kcmil • 636 (30/19) Egret kcmil • 666.6 (24/7) Flamingo kcmil • 715.5 (54/7) Crow kcmil • 715.5 (24/7) Stilt kcmil • 715.5 (26/7) Starling kcmil • 715.5 (30/19) Redwing kcmil • 795 (54/7) Condor kcmil • 795 (26/7) Drake kcmil
Conductor - ACSR Str Tap Range	556.5 (24/7) Parakeet kcmil-795 (26/7) Drake kcmil
Conductor - ACSR Str Tap	• 556.5 (24/7) Parakeet kcmil • 556.5 (26/7) Dove kcmil • 556.5 (30/7) Eagle kcmil • 605 (24/7) Peacock kcmil • 605 (26/7) Squab kcmil • 605 (30/19) Teal kcmil • 636 (24/7) Rook kcmil • 636 (26/7) Grosbeak kcmil • 636 (30/19) Egret kcmil • 666.6 (24/7) Flamingo kcmil • 715.5 (54/7) Crow kcmil • 715.5 (24/7) Stilt kcmil • 715.5 (26/7) Starling kcmil • 715.5 (30/19) Redwing kcmil • 795 (54/7) Condor kcmil • 795 (26/7) Drake kcmil
Conductor - Copper Str Run Range	600 kcmil-900 kcmil
Conductor - Copper Str Run	• 600 kcmil • 700 kcmil • 750 kcmil

	• 800 kcmil • 850 kcmil • 900 kcmil
Conductor - Copper Str Tap Range	600 kcmil-900 kcmil
Conductor - Copper Str Tap	• 600 kcmil • 700 kcmil • 750 kcmil • 800 kcmil • 850 kcmil • 900 kcmil

Dimensions

Package Height	0.000 in
Dimension - Height mm	75.4 mm
Dimension - Height inch	2.97 in
Dimension - Height fraction	2-97/100 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	117 mm
Dimension - Width fraction	1-37/50 in
Dimension - Width mm	44 mm
Dimension - Width inch	1.74 in
Dimension - Length Overall inch	4.62 in



General

Product Family	Utility Overhead & Underground Distribution>Compression Tap Connectors>H-Taps
Trade Name	HYCRIMP™
Die Index	KR
Prefilled Oxide Inhibitor	Y
Plated	No
Sub Brand	HYCRIMP
Product Type	Compression
UPC	781810139851
Type	YHR
Material	Aluminum
Plating Type	Unplated
UPC 14 Digit GTIN	00781810139851

Logistics

Minimum Pack Quantity	10
Pallet Quantity	440
Carton Quantity	10

Product Assets

[Catalog \[English\]](#)