


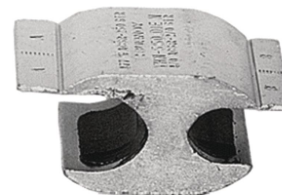

YHR950, Line Tap for Cu, AL, ACSR, Compact

By Burndy
Catalog # [YHR950](#)

Compression Line Tap for Copper, AL or ACSR and Compact Conductors, groove A(Run) ACSR: 336.4(18/1) - 954 (45/7)



Features

- Wide range, universal and reversible Figure H-Shaped aluminum connector
- Conductors are separated by the shape of the connector
- Bendable tabs secure both run and tap conductors freeing the installer to work with the installation tool
- Massive aluminum design miniizes corrosion due to galvanic corrosion
- Prefilled with PENETROX Joint Compound and individually packaged

Application

For Copper, Aluminum Or ACSR And Compact Conductors

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	336 kcmil-1000 kcmil
Conductor - AL Str Run	• 336 kcmil • 350 kcmil • 397 kcmil • 400 kcmil • 450 kcmil • 477 kcmil • 500 kcmil • 550 kcmil • 556 kcmil • 600 kcmil • 636 kcmil • 650 kcmil • 700 kcmil • 715 kcmil • 750 kcmil • 795 kcmil • 800 kcmil • 874 kcmil • 900 kcmil • 954 kcmil

Conductor - AL Str Tap Range
Conductor - AL Str Tap

- 1000 kcmil
- 336 kcmil-1000 kcmil
- 336 kcmil
 - 350 kcmil
 - 397 kcmil
 - 400 kcmil
 - 450 kcmil
 - 477 kcmil
 - 500 kcmil
 - 550 kcmil
 - 556 kcmil
 - 600 kcmil
 - 636 kcmil
 - 650 kcmil
 - 700 kcmil
 - 715 kcmil
 - 750 kcmil
 - 795 kcmil
 - 800 kcmil
 - 874 kcmil
 - 900 kcmil
 - 954 kcmil
 - 1000 kcmil

Conductor - ACSR Str Run Range
Conductor - ACSR Str Run

336.4 (24/7) Parakeet kcmil-954 (45/7) Rail kcmil

- 336.4 (24/7) Parakeet kcmil
- 556.5 (26/7) Dove kcmil
- 556.5 (30/7) Eagle kcmil
- 605 (24/7) Peacock kcmil
- 605 (26/7) Squab kcmil
- 605 (30/19) Teal kcmil
- 636 (24/7) Rook kcmil
- 636 (26/7) Grosbeak kcmil
- 636 (30/19) Egret kcmil
- 666.6 (24/7) Flamingo kcmil
- 715.5 (54/7) Crow kcmil
- 715.5 (24/7) Stilt kcmil
- 715.5 (26/7) Starling kcmil
- 715.5 (30/19) Redwing kcmil
- 795 (54/7) Condor kcmil
- 795 (26/7) Drake kcmil
- 795 (30/19) Mallard kcmil
- 874.5 54/7 Condor kcmil
- 900 (54/7) Canary kcmil
- 954 (45/7) Rail kcmil

Conductor - ACSR Str Tap Range
Conductor - ACSR Str Tap

336.4 (18/1) Merlin kcmil-954 (45/7) Rail kcmil

Conductor - ACSR Str Tap

- 336.4 (18/1) Merlin kcmil
- 336.4 (26/7) Linnet kcmil
- 336.4 (30/7) Oriole kcmil
- 397.5 (18/1) Chickadee kcmil
- 397.5 (24/7) Brant kcmil
- 397.5 (26/7) Ibis kcmil
- 397.5 (30/7) Larkspur kcmil
- 477.0 (18/1) Pelican kcmil
- 477.0 (24/7) Flicker kcmil
- 477.0 (26/7) Hawk kcmil
- 477. (30/7) Hen kcmil
- 500.0 (30/7) Heron kcmil
- 556.5 (24/7) Parakeet kcmil
- 556.5 (26/7) Dove kcmil
- 556.5 (30/7) Eagle kcmil
- 605 (24/7) Peacock kcmil
- 605 (26/7) Squab kcmil
- 605 (30/19) Teal kcmil
- 636 (24/7) Rook kcmil
- 636 (26/7) Grosbeak kcmil
- 636 (30/19) Egret kcmil
- 666.6 (24/7) Flamingo kcmil
- 715.5 (54/7) Crow kcmil
- 715.5 (24/7) Stilt kcmil
- 715.5 (26/7) Starling kcmil
- 715.5 (30/19) Redwing kcmil
- 795 (54/7) Condor kcmil
- 795 (26/7) Drake kcmil
- 795 (30/19) Mallard kcmil
- 874.5 (54/7) Crane kcmil
- 900 (54/7) Canary kcmil
- 954 (45/7) Rail kcmil

Conductor - Copper Str Run Range

350 kcmil-1000 kcmil

Conductor - Copper Str Run

- 350 kcmil
- 400 kcmil
- 450 kcmil
- 500 kcmil
- 550 kcmil
- 600 kcmil
- 700 kcmil
- 750 kcmil
- 800 kcmil
- 850 kcmil
- 900 kcmil
- 1000 kcmil

Conductor - Copper Str Tap Range

350 kcmil-1000 kcmil

Conductor - Copper Str Tap

- 350 kcmil
- 400 kcmil
- 450 kcmil

- 500 kcmil
- 550 kcmil
- 600 kcmil
- 700 kcmil
- 750 kcmil
- 800 kcmil
- 850 kcmil
- 900 kcmil
- 1000 kcmil

Dimensions

Package Height	0.000 in
Dimension - Height mm	79.8 mm
Dimension - Height inch	3.14 in
Dimension - Height fraction	3-7/50 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	152 mm
Dimension - Width fraction	1-33/50 in
Dimension - Width mm	42 mm
Dimension - Width inch	1.66 in
Dimension - Length Overall inch	6.00 in

General

Product Family	Utility Overhead & Underground Distribution>Compression Tap Connectors>H-Taps
Trade Name	HYCRIMP™
Die Index	KR
Prefilled Oxide Inhibitor	Y
Plated	No
Sub Brand	HYCRIMP
Product Type	Compression
UPC	781810139905
Type	YHR
Construction Material - Main	Aluminum
Material	Aluminum
Plating Type	Unplated
UPC 14 Digit GTIN	00781810139905

Logistics

Minimum Pack Quantity	1
Pallet Quantity	270
Carton Quantity	10

Product Assets

[Catalog \[English\]](#)



A Hubbell brand