




YHSQ14M25X03, Heat Shrink Male Quick Disconnect For 16 - 14 AWG (.25 x .03)

By Burndy
Catalog # [YHSQ14M25X03](#)

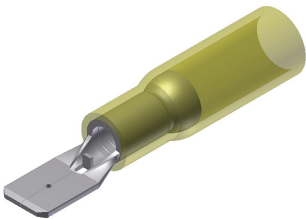

Heat Shrink Male Quick Disconnect For 16 - 14 AWG (.25 x .03)

Features

- Color-coded, imprinted with wire size
- Serrated barrels offer maximum wire contact and tensile strength
- Electro-tin plated for corrosion resistance

Application

For Use On Copper Conductor

Specifications

Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	No
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor - Copper Str Size	• 16 AWG • 14 AWG
Conductor - Copper Solid Size	• 16 AWG • 15 AWG • 14 AWG
Conductor - Copper Solid Size Range	16 AWG-14 AWG
Conductor Size	16 - 14 AWG
Conductor - Copper Str Size Range	16 AWG - 14 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size

Configuration

Connector Type	Male Quick Disconnect
----------------	-----------------------

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - L Length Overall mm	32 mm
Dimension - Pad Width inch	0.25 in
Package Height	0.000 in
Dimension - Strip Length inch	5/16
Dimension - B Length fraction	2/9 in
Dimension - B Length inch	0.22 in
Dimension - Length Overall inch	1.25 in

General

Insulation Type	Heat Shrink
Trade Name	HYDENT™
Insulation	Y
Sub Brand	HYDENT
Plated	Y
Type	YHS
UPC 14 Digit GTIN	00781810477113
Material	Copper
Plating Type	Tin
UPC	781810477113

Logistics

Minimum Pack Quantity	100
Packaging Type	Bag
Carton Quantity	1200
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)