




YHSQ18F25X03, Heat Shrink Female Quick Disconnect For 22 - 18 AWG (.25 x .03)

By Burndy

Catalog # [YHSQ18F25X03](#)

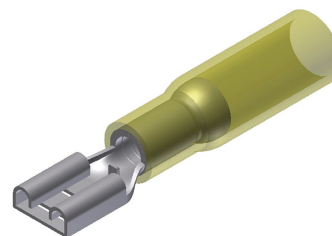

Heat Shrink Female Quick Disconnect For 22 - 18 AWG (.25 x .03)

Features

- Color-coded, imprinted with wire size
- Serrated barrels offer maximum wire contact and tensile strength
- Electro-tin plated for corrosion resistance

Application

For Use On Copper Conductor

Specifications

Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	No
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	22 - 18 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size

Configuration

Connector Type	Female Quick Disconnect
----------------	-------------------------

Dimensions

Package Length	0.000 in
----------------	----------

Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - L Length Overall	32 mm
Dimension - Pad Width inch	0.30 in
Package Height	0.000 in
Dimension - Strip Length inch	5/16
Dimension - B Length fraction	2/9 in
Dimension - B Length inch	0.22 in
Dimension - Length Overall	1.27 in
inch	

General

Insulation Type	Heat Shrink
Trade Name	HYDENT™
Insulation	Y
Sub Brand	HYDENT
Plated	Y
Type	YHS
UPC 14 Digit GTIN	00781810477083
Material	Copper
Plating Type	Tin
UPC	781810477083

Logistics

Minimum Pack Quantity	100
Packaging Type	Bag
Carton Quantity	1200
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)



A Hubbell brand