



YIPC348CWC, Aluminum Compression H-Tap, Run: 500 kcmil AL PV Wire; Tap: #10-8 AWG CU PV Wire

By Burndy
Catalog # [YIPC348CWC](#)

Compression Insulation Piercing Connector Accommodating 500 kcmil AL PV Wire and 10 AWG-8 AWG CU PV Wire

Features

- Connector & Cover Assembly sold as a kit, includes installation instructions
- UL Listed Sealed Wire Connector System with Raintight Rating and Sunlight Resistance. Category ZMWQ testing in accordance with UL486D
- Connector Piercing Features: Main/Run groove has three insulating piercing teeth and two insulation piercing legs to maintain connectivity and thermal stability
- Cover: Polycarbonate material UL 94 V-O flame rating and sunlight/UV resistant
- Connector placement guide for proper seating of connector to cover

Application

Wire Tap


Specifications

Industry Standard(s) UL 468A-468B

Conductor

Conductor - AL Str Run 500 kcmil

Configuration

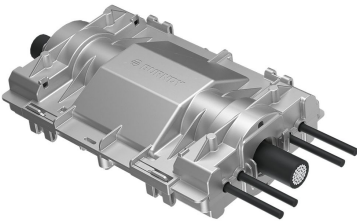

Connector Type H-Tap

Dimensions

Height	2.95 in
Width	14.57 in
Package Height	0.000 in
Length	9.7 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimensions	9.7 in x 14.57 in x 2.95 in

General

UPC	621945688155
Trade Name	HYPIERCE™
Type	Compression Taps
Die Index	500

Logistics

Pallet Quantity	224
Carton Quantity	14

Product Assets

[Catalog \[English\]](#)