



YIPC368CWC, Aluminum Compression H-Tap, Run: 600 kcmil AL PV Wire; Tap: #10-8 AWG CU PV Wire

By Burndy
Catalog # [YIPC368CWC](#)

Compression Insulation Piercing Connector Accommodating 600 kcmil AL PV Wire and 10-8 AWG CU PV Wire

Features

- Connector & Cover Assembly sold as a kit, includes installation instructions
- UL Listed Sealed Wire Connector System with Raintight Rating and Sunlight Resistance. Category ZMWQ testing in accordance with UL486D
- Connector Piercing Features: Main/Run groove has three insulating piercing teeth and two insulation piercing legs to maintain connectivity and thermal stability
- Cover: Polycarbonate material UL 94 V-O flame rating and sunlight/UV resistant
- Connector placement guide for proper seating of connector to cover

Application


Wire Tap

Specifications

Industry Standard(s) UL 468A-468B

Conductor

Conductor - AL Str Run 600 kcmil

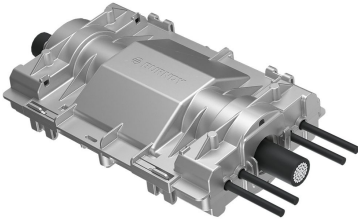

Configuration

Connector Type H-Tap

Dimensions

Package Height 0.000 in
Package Weight 0.000 lb.
Package Length 0.000 in
Package Width 0.000 in

General

UPC 621945688162
Trade Name HYPIERCE™
Type Compression Taps
Die Index 600

Logistics

Pallet Quantity 1
Carton Quantity 14

Product Assets

[Catalog \[English\]](#)