




YKA342N, Copper Disconnectable Terminal w/Fixed Hardware

By Burndy
Catalog # [YKA342N](#)

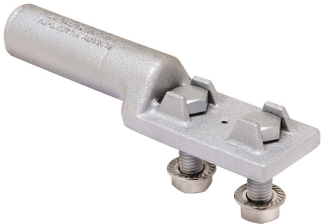

HYLUG™, Copper Disconnectable Compression Terminal, With Fixed H/W, 2 Holes, 500 KCMIL Cu, 1/2" Stud

Features

- Copper Disconnectable Terminal with Fixed Hardware

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	500 kcmil
Range	
Conductor - Copper Str Size	500 kcmil

Configuration

Physical Attribute - Number of Crimps Required	2
Physical Attribute - Number of Holes	2
Connector Type	Terminal

Dimensions

Dimension - Pad Width inch	1.88 in
Physical Attribute - Tongue Angle	Straight
Dimension - B Length fraction	2-9/17 in

Dimension - E Spacing between Holes fraction 1-3/4 in

Dimension - L Length Overall mm 166 mm

Dimension - B Length inch 2.53 in

Dimension - Outside Diameter inch 1.38 in

Dimension - N inch 0.63 in

Dimension - Length Overall inch 6.52 in

Dimension - Strip Length inch 2- 5/8 in

Dimension - Stud Size inch 1/2 in

General

Plated	Y
Trade Name	HYLUG™
Die Index	210
UPC	781810014905
Prefilled Oxide Inhibitor	N
Material	Copper
Plating Type	Tin
UPC 14 Digit GTIN	00781810014905

Logistics

Minimum Pack Quantity	1
Pallet Quantity	888
Carton Quantity	8

Product Assets

[Catalog \[English\]](#)