




YP25U25, Figure 3-shaped Aluminum Connector with adjustable spacer

By Burndy
Catalog # [YP25U25](#)

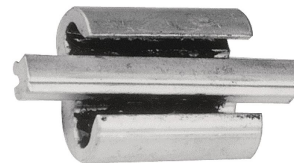

Wide range, universal and reversible, Figure 3 shaped aluminum connector with adjustable overhanging spacer that separates conductors, Conductor Groove A Solid: 2/0, 3/0.

Features

- Wide range universal and reversible, Figure 3-shaped aluminum connector features adjustable overhanging spacer that separates conductors
- Spacer holds run or tap in place, permitting lineman to either approach the line ready to crimp or to assemble connector and tap on run and then crimp
- Massive aluminum design minimizes conductor corrosion due to galvanic action
- Pre-filled with PENETROX joint compound and stripsealed

Application

For Copper, Aluminum Or ACSR Conductors

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size A	• 1 AWG • 1/0 AWG
Conductor - AL Str Size B	• 1 AWG • 1/0 AWG
Conductor - AL Str Size A Range	1 AWG-1/0 AWG
Conductor - AL Str Size B Range	1 AWG-1/0 AWG
Conductor - ACSR Str Size A	• 1 (6/1) Robin AWG • 1/0 (6/1) Raven AWG
Conductor - ACSR Str Size B	• 1 (6/1) Robin AWG • 1/0 (6/1) Raven AWG
Conductor - ACSR Str Size A Range	1 (6/1) Robin AWG-1/0 (6/1) Raven AWG
Conductor - ACSR Str Size B Range	1 (6/1) Robin AWG-1/0 (6/1) Raven AWG
Conductor - Copper Str Size A	• 1 AWG • 1/0 • 2/0 AWG
Conductor - Copper Str Size B	• 1 AWG • 1/0

Conductor - Copper Str Size A Range	• 2/0 AWG 1 AWG-2/0 AWG
Conductor - Copper Solid Size A	• 2/0 AWG • 3/0 AWG
Conductor - Copper Solid Size B	• 2/0 AWG • 3/0 AWG
Conductor - Copper Solid Size A Range	2/0 AWG-3/0 AWG
Conductor - Copper Solid Size B Range	2/0 AWG-3/0 AWG
Conductor - Copper Str Size B Range	1 AWG-2/0 AWG

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Dimension - Height inch	1.70 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - Width inch	0.97 in
Dimension - Length Overall inch	1.69 in

General

Product Family	Utility Overhead & Underground Distribution>Compression Tap Connectors>C-Taps
Trade Name	CABELOK™ CRIMPIT™
Die Index	D3
Prefilled Oxide Inhibitor	Y
Plated	No
Sub Brand	CABELOK CRIMPIT
Product Type	Compression
UPC	781810130322
Type	YP-U
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810130322
UPC 14 Digit GTIN	00781810130322

Logistics

Minimum Pack Quantity	1
Pallet Quantity	4000
Carton Quantity	100



A Hubbell brand