



YP26AU2, Figure 3-shaped Aluminum Connector with adjustable spacer

By Burndy
Catalog # [YP26AU2](#)

Wide range, universal and reversible, Figure 3 shaped aluminum connector with adjustable overhanging spacer that separates conductors, Conductor Groove A Solid: 1, 1/0, 2/0, 3/0.

Features

- Wide range universal and reversible, Figure 3-shaped aluminum connector features adjustable overhanging spacer that separates conductors
- Spacer holds run or tap in place, permitting lineman to either approach the line ready to crimp or to assemble connector and tap on run and then crimp
- Massive aluminum design minimizes conductor corrosion due to galvanic action
- Pre-filled with PENETROX joint compound and stripsealed

Application


For Copper, Aluminum Or ACSR Conductors

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size A	• 3 AWG • 2 AWG • 1 AWG • 1/0 AWG
Conductor - AL Str Size B	• 6 AWG • 4 AWG • 3 AWG • 2 AWG
Conductor - AL Str Size A Range	3 AWG-1/0 AWG
Conductor - AL Str Size B Range	6 AWG-2 AWG
Conductor - ACSR Str Size A	• 3 (6/1) Swallow AWG • 2 (6/1) Sparrow AWG • 2 (7/1) Sparate AWG • 1 (6/1) Robin AWG • 1/0 (6/1) Raven AWG
Conductor - ACSR Str Size B	• 6 (6/1) Turkey AWG • 5 (6/1) Thrush AWG • 4 (6/1) Swan AWG • 4 (7/1) Swanate AWG

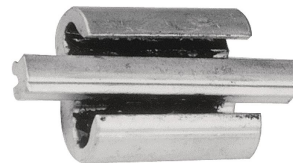

Conductor - ACSR Str Size A Range	• 3 (6/1) Swallow AWG • 2 (6/1) Sparrow AWG 3 (6/1) Swallow AWG-1/0 (6/1) Raven AWG
Conductor - ACSR Str Size B Range	6 (6/1) Turkey AWG-2 (6/1) Sparrow AWG
Conductor - Copper Str Size A	• 2 AWG • 1 AWG • 1/0 • 2/0 AWG
Conductor - Copper Str Size B	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG
Conductor - Copper Str Size A Range	2 AWG-2/0 AWG
Conductor - Copper Solid Size A	• 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG
Conductor - Copper Solid Size B	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG
Conductor - Copper Solid Size A Range	1 AWG-3/0 AWG
Conductor - Copper Solid Size B Range	1 AWG-3/0 AWG
Conductor - Copper Str Size B Range	6 AWG-1 AWG

Dimensions

Package Height	0.000 in
Dimension - Height inch	1.30 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - Width inch	0.72 in
Dimension - Length Overall inch	1.50 in

General

Product Family	Utility Overhead & Underground Distribution>Compression Tap Connectors>C-Taps	Plating Type UPC 12 Digit UPC 14 Digit GTIN	Unplated 781810130650 00781810130650
Trade Name	CABELOK™ CRIMPIT™	Logistics	
Die Index	O	Minimum Pack Quantity	1
Prefilled Oxide Inhibitor	Y	Pallet Quantity	5000
Plated	No	Carton Quantity	50
Sub Brand	CABELOK CRIMPIT	Product Assets	
Product Type	Compression	Catalog [English]	
UPC	781810130650		
Type	YP-U		
Material	Aluminum		



A Hubbell brand