


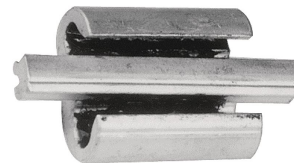

YP27AU2, Figure 3-shaped Aluminum Connector with adjustable spacer

By Burndy
Catalog # [YP27AU2](#)

Wide range, universal and reversible, Figure 3 shaped aluminum connector with adjustable overhanging spacer that separates conductors, Conductor Groove A Solid: 2/0, 3/0, 4/0.



Features

- Wide range universal and reversible, Figure 3-shaped aluminum connector features adjustable overhanging spacer that separates conductors
- Spacer holds run or tap in place, permitting lineman to either approach the line ready to crimp or to assemble connector and tap on run and then crimp
- Massive aluminum design minimizes conductor corrosion due to galvanic action
- Pre-filled with PENETROX joint compound and stripsealed

Application

For Copper, Aluminum Or ACSR Conductors

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size A	• 1/0 AWG • 2/0 AWG
Conductor - AL Str Size B	• 4 AWG • 3 AWG • 2 AWG
Conductor - AL Str Size A Range	1/0 AWG-2/0 AWG
Conductor - AL Str Size B Range	4 AWG-2 AWG
Conductor - ACSR Str Size A	• 1/0 (6/1) Raven AWG • 2/0 (6/1) Quail AWG
Conductor - ACSR Str Size B	• 4 (6/1) Swan AWG • 4 (7/1) Swanate AWG • 3 (6/1) Swallow AWG • 2 (6/1) Sparrow AWG • 2 (7/1) Sparate AWG
Conductor - ACSR Str Size A Range	1/0 (6/1) Raven AWG-2/0 (6/1) Quail AWG
Conductor - ACSR Str Size B Range	4 (6/1) Swan AWG-2 (7/1) Sparate AWG
Conductor - Copper Str Size A	• 1/0

Conductor - Copper Str Size B	• 2/0 AWG • 3/0 AWG • 3 AWG • 2 AWG • 1 AWG
Conductor - Copper Str Size A Range	1/0 -3/0 AWG
Conductor - Copper Solid Size A	• 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Solid Size B	• 2 AWG • 1 AWG • 1/0 AWG
Conductor - Copper Solid Size A Range	2/0 AWG-4/0 AWG
Conductor - Copper Solid Size B Range	2/0 AWG-4/0 AWG
Conductor - Copper Str Size B Range	3 AWG-1 AWG

Dimensions

Package Height	0.000 in
Dimension - Height inch	1.70 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - Width inch	0.97 in
Dimension - Length Overall inch	1.69 in

General

Product Family	Utility Overhead & Underground Distribution>Compression Tap Connectors>C-Taps
Trade Name	CABELOK™ CRIMPIT™
Die Index	D3
Prefilled Oxide Inhibitor	Y
Plated	No
Sub Brand	CABELOK CRIMPIT
Product Type	Compression
UPC	781810133989
Type	YP-U
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810133989
UPC 14 Digit GTIN	00781810133989

Logistics

Minimum Pack Quantity	1
Pallet Quantity	3400

Carton Quantity50

Product Assets

[Catalog \[English\]](#)



A Hubbell brand