

YP2C2, Figure 6-shaped Copper Tap Connector

By Burndy
Catalog # [YP2C2](#)

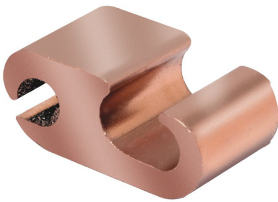


Figure 6 - shaped, wide range-taking CU compression tap connector for primary service taps and secondary service drops, Width: .75 IN

Features

- Compression tap connector for primary service taps and secondary service drops
- Connector can be gripped in tool and slipped over the line for easy installation

Application

For Extra Wide Range Of Copper And Primary Service Taps And Secondary Service Drops

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	6 AWG-2 AWG
Conductor - Copper Str Run	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG
Conductor - Copper Solid Run	6 AWG
Conductor - Copper Solid Tap	6 AWG
Conductor - Copper Str Tap Range	6 AWG-2 AWG
Conductor - Copper Str Tap	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Package Height	0.000 in
Dimension - Height mm	37 mm
Dimension - Height inch	1.45 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	19 mm
Dimension - Length Overall inch	0.75 in

General

Plated	Yes
Product Family	Utility Overhead & Underground Distribution>Compression Tap Connectors>YPC Figure 6
Trade Name	CRIMPIT™
Sub Brand	CRIMPIT
Die Index	O
Product Type	Compression
UPC	781810117903
Type	YP-C
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810117903
UPC 14 Digit GTIN	00781810117903

Logistics

Minimum Pack Quantity	1
Pallet Quantity	11600
Carton Quantity	100

Product Assets

[Catalog \[English\]](#)