

YP2U3, Figure 3-shaped Aluminum Connector with adjustable spacer

By Burndy
Catalog # [YP2U3](#)

Wide range, universal and reversible, Figure 3 shaped aluminum connector with adjustable overhanging spacer that separates conductors, Conductor Groove A Solid: 6, 4, 3, 2.

Features

- Wide range universal and reversible, Figure 3-shaped aluminum connector features adjustable overhanging spacer that separates conductors
- Spacer holds run or tap in place, permitting lineman to either approach the line ready to crimp or to assemble connector and tap on run and then crimp
- Massive aluminum design minimizes conductor corrosion due to galvanic action
- Pre-filled with PENETROX joint compound and stripsealed

Application


For Copper, Aluminum Or ACSR Conductors

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size A	• 6 AWG • 4 AWG
Conductor - AL Str Size B	• 6 AWG • 4 AWG
Conductor - AL Str Size A Range	6 AWG-4 AWG
Conductor - AL Str Size B Range	6 AWG-4 AWG
Conductor - ACSR Str Size A	• 6 (6/1) Turkey AWG • 5 (6/1) Thrush AWG • 4 (6/1) Swan AWG • 4 (7/1) Swanate AWG
Conductor - ACSR Str Size B	• 6 (6/1) Turkey AWG • 5 (6/1) Thrush AWG • 4 (6/1) Swan AWG • 4 (7/1) Swanate AWG
Conductor - ACSR Str Size A Range	6 (6/1) Turkey AWG-4 (7/1) Swanate AWG
Conductor - ACSR Str Size B Range	6 (6/1) Turkey AWG-4 (7/1) Swanate AWG
Conductor - Copper Str Size A	• 6 AWG

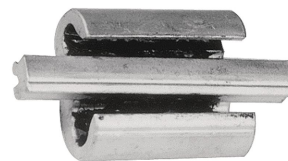

Conductor - Copper Str Size B	• 5 AWG • 4 AWG • 3 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG
Conductor - Copper Str Size A Range	6 AWG-3 AWG
Conductor - Copper Solid Size A	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG
Conductor - Copper Solid Size B	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG
Conductor - Copper Solid Size A Range	6 AWG-2 AWG
Conductor - Copper Solid Size B Range	6 AWG-2 AWG
Conductor - Copper Str Size B Range	6 AWG-3 AWG

Dimensions

Package Height	0.000 in
Dimension - Height inch	1.30 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	38 mm
Dimension - Width inch	0.72 in
Dimension - Length Overall inch	1.50 in

General

Product Family	Utility Overhead & Underground Distribution>Compression Tap Connectors>C-Taps
Trade Name	CABELOK™ CRIMPIT™
Die Index	O
Prefilled Oxide Inhibitor	Y
Plated	No
Sub Brand	CABELOK CRIMPIT

Product Type	Compression
UPC	781810131732
Type	YP-U
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810131732
UPC 14 Digit GTIN	00781810131732

Logistics

Minimum Pack Quantity	1
Pallet Quantity	3700
Carton Quantity	50

Product Assets

[Catalog \[English\]](#)



A Hubbell brand