




YR2C2WT, Compression Splice, #2 AWG Cu, Long Barrel

By Burndy
Catalog # [YR2C2WT](#)

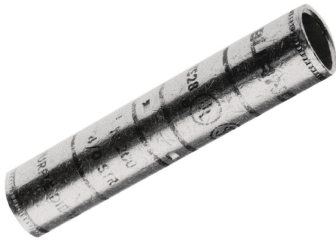

2 AWG, CU, Long Barrel SPLICE

Application

Wire Splice

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor Size	2 AWG-2 AWG
Conductor - Copper Solid Size	2 AWG
Conductor - Copper Solid Size Range	2 AWG
Conductor - Material	COPPER
Wire Size	#2 AWG
Conductor Type	CODE
Conductor - Copper Str Size Range	2 AWG
Conductor - Copper Str Size	2 AWG

Configuration

Connector Type	STANDARD BARREL
----------------	-----------------

Current

Voltage - Maximum	35000
-------------------	-------

Dimensions

Package Height	0.000 in
----------------	----------

Dimension - B Length fraction	1-1/4 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	77 mm
Dimension - B Length inch	1.25 in
Dimension - Outside Diameter inch	0.42 in
Dimension - Length Overall inch	3.03 in
Dimension - Strip Length inch	1-3/8

General

Feature - Barrel Type	Long
Plated	Y
Color Code	Brown
Die Index	10
UPC	781810064771
Material	COPPER
Plating Type	Tin - Electro Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810064771
UPC 14 Digit GTIN	00781810064771

Logistics

Carton Quantity	25
-----------------	----

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)