




BURNDY

[YRB31U25TW, Aluminum HYREDUCER Splice, Tin Plated](#)

By Burndy

Catalog # [YRB31U25TW](#)

HYREDUCER™, Hot Tin dipped, 5.43 in long

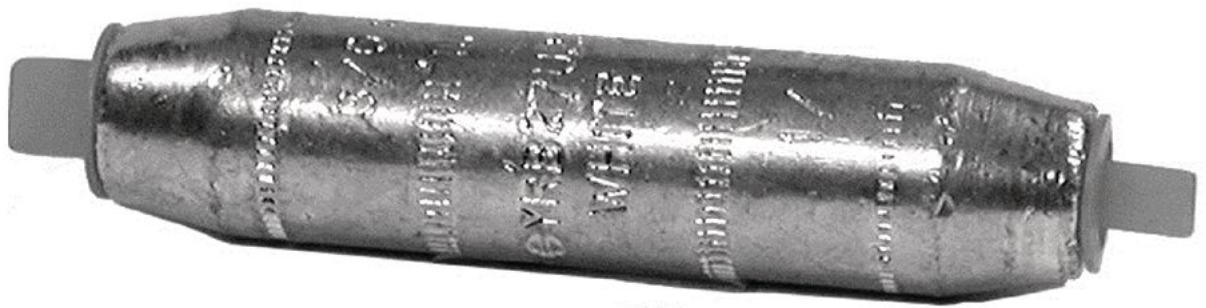

Features

- Aluminum Compression Reducing Splice
- Hot Tin Dipped

Specifications

Certification - ETL

No

Certification - UL Recognized

No

Standards - RoHS Compliance Status

CM

Certification - cULus
No
UL Listed
No
Certification - CSA Approved
No

Conductor

Conductor - Copper Str Size A
350 kcmil
Conductor - Copper Str Size B
1/0 AWG
Conductor - AL Str Size A
350 kcmil
Conductor - AL Str Size B
1/0 AWG

Configuration

Connector Type
Reducer

Dimensions

Dimension - B Length fraction
2-17/50 in
Dimension - B Length inch
2.34 in
Dimension - Length Overall inch
5.43 in
Dimension - Strip Length inch
2.5 in

General

Color Code
Brown
Trade Name
HYREDUCER™
Die Index
299
UPC
781810209097
Material
Aluminum
Plating Type
Tin - Hot Dipped
UPC 14 Digit GTIN
00781810209097

Logistics

Minimum Pack Quantity
1
Pallet Quantity
5550
Carton Quantity
25

Product Assets

[Catalog.\[English\]](#)



A Hubbell brand
© 2026 Hubbell Incorporated. All rights reserved
BRDY-YRB31U25TW-SPEC-EN | REV 5/2026