




YS28T, Compression Splice, 4/0 AWG Cu, Tapered End

By Burndy
Catalog # [YS28T](#)

4/0 AWG, CU, Taper End SPLICE

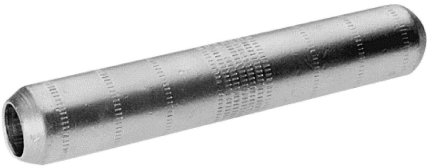

Features

- Copper seamless barrel designed with tapered ends per EEL Standard TD160, for use on voltages 5kV through 35kV, this aids in preventing corona emission and simplifies taping for lower installation cost
- Barrel also features internal chamfer at wire entry to ensure smooth insertion of wire, preventing possible damage of the wire strands during insertion
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements

Application

T-Connector

Specifications

Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Buy American Compliant	Contact Manufacturer
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Size	4/0 AWG
Conductor - Material	COPPER
Wire Size	4/0 AWG
Conductor Type	CODE
Conductor - Copper Str Size Range	4/0 AWG

Configuration

Connector Type	T-CONNECTOR
----------------	-------------

Current

Voltage Rating	35 kV
----------------	-------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

Color Code	Purple
Trade Name	HYLINK™
Sub Brand	HYLINK
Die Index	15
UPC	781810001226
Type	YS-T, High Voltage, Standard Barrel
Material	Copper
Finish Type	Tin-Plated

Logistics

Minimum Pack Quantity	1
Pallet Quantity	14800
Carton Quantity	100

Product Assets

[Catalog \[English\]](#)