


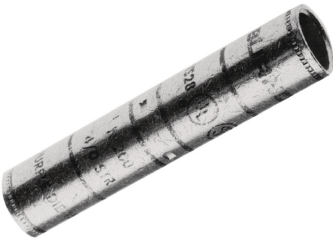

YS28UCG1, Splice Kit - Insulated

By Burndy
Catalog # YS28UCG1

URD Insulator Splice Kit, 4/0 AWG Comp, 4/0 Str Al, 4/0 AWG (6-1) ACSR, 4/0 Str Cu, 600 V



Features

- URD Insulator Splice Kit

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size A	4/0 AWG
Conductor - Copper Str Size B	4/0 AWG
Conductor - Copper Str Size A	4/0 AWG
Range	
Conductor - AL Str Size A	4/0 AWG
Conductor - AL Str Size B	4/0 AWG
Conductor - AL Str Size A	4/0 AWG
Range	
Conductor - AL Str Size B	4/0 AWG
Range	
Conductor - ACSR Str Size A	4/0 (6/1) Penguin AWG
Conductor - ACSR Str Size B	4/0 (6/1) Penguin AWG
Conductor - ACSR Str Size A	4/0 (6/1) Penguin AWG
Range	
Conductor - Copper Str Size B	4/0 AWG
Range	
Conductor - ACSR Str Size B	4/0 (6/1) Penguin AWG
Range	

Configuration

Connector Type	Splice
----------------	--------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	1.9 in
Dimension - Length Overall	4.12 in
inch	

General

Plated	N
Insulation Type	Diaform
Die Index	• 249 • 840
UPC	781810187906
Insulation	Y
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810187906
UPC 14 Digit GTIN	00781810187906

Logistics

Minimum Pack Quantity	1
Pallet Quantity	900
Carton Quantity	10

Product Assets

[Catalog \[English\]](#)