




YS29, Cu Compression Splice, Long Barrel, 250 kcmil

By Burndy
Catalog # [YS29](#)

250 kcmil, CU, Long Barrel SPLICE

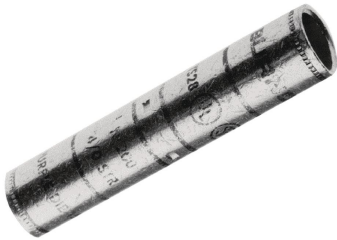

Features

- Copper seamless barrel with center stop indentations to indicate when wire is fully inserted into each side of the barrel
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors clearly marked with color coding

Application

Wire Splice

Specifications

Buy American Compliant	Contact Manufacturer
EU RoHS Indicator	Yes
Buy America(n) Qualified	TAA Compliant (All status valid till December 2026)
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Material	COPPER
Wire Size	250 kcmil
Conductor - Copper Str Size	250 kcmil
Conductor Size	250 KCMIL
Conductor - Copper Str Navy Size	250 (61) Navy
Conductor Type	CODE
Conductor - Copper Str Size Range	250 kcmil

Configuration

Connector Type	LONG BARREL
----------------	-------------

Current

Voltage Rating	35 kV
Voltage - Maximum	35000

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	91 mm
Dimension - Strip Length inch	1-11/16
Dimension - B Length inch	1.58 in
Dimension - Length Overall inch	3.58 in

General

Trade Name	HYLINK™
Die Index	16
Feature - Barrel Type	Long
Feature - Barrel Style	Chamfered
Plated	Y
Color Code	Yellow
Sub Brand	HYLINK
UPC	781810507957
Type	YS, Long Barrel
Material	Copper
Plating Type	Tin - Electro Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810507957
UPC 14 Digit GTIN	00781810507957

Logistics

Minimum Pack Quantity	1
Carton Quantity	10

Product Assets

[Catalog \[English\]](#)



A Hubbell brand