


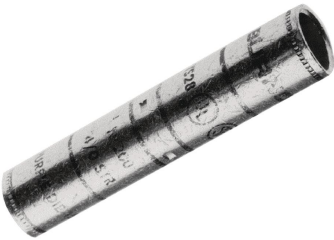

YS37, Compression Splice, 650 kcmil Cu, Long Barrel

By Burndy
Catalog # [YS37](#)

Copper Compression Splice, 650 Kcmil, 6.10" Splice Length, Long Barrel, Tin Plated.



Features

- Copper seamless barrel with center stop indentations to indicate when wire is fully inserted into each side of the barrel
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors clearly marked with color coding

Application

Wire Splice

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Size	650 KCMIL
Conductor - Copper Str Navy Size	650 (127)
Conductor - Material	COPPER
Conductor Type	CODE
Conductor - Copper Str Size Range	650 kcmil
Conductor - Copper Str Size	650

Configuration

Connector Type	LONG BARREL
----------------	-------------

Current

Voltage Rating	35 kV
Voltage - Maximum	35000

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	155 mm
Dimension - B Length inch	2.75 in
Dimension - Length Overall inch	6.10 in
Dimension - Strip Length inch	2-13/16

General

Feature - Barrel Type	Long
Feature - Barrel Style	Chamfered
Plated	Y
Color Code	Orange
Trade Name	HYLINK™
Die Index	23
UPC	781810080863
Material	Copper
Plating Type	Tin - Electro Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810080863
UPC 14 Digit GTIN	00781810080863

Logistics

Minimum Pack Quantity	6
Carton Quantity	6

Product Assets

[Catalog \[English\]](#)