




YSE10HHS, Heat Shrink Splice For 12 - 10 AWG

By Burndy
Catalog # [YSE10HHS](#)

Heat Shrink Splice For 12 - 10 AWG

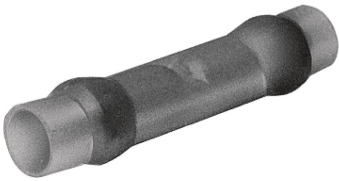

Features

- Manufactured from tin plated, seamless electrolytic copper tubing with integral barrel for maximum conductivity and tensile strength, plus excellent cable support and strain relief
- Smooth funnel entry provides easy wire insertion
- Transparent heat shrink insulation provides waterproofing and weather resistance

Application

Butt Connector

Specifications

Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - CSA Approved	No
UL Listed	No
Buy America(n) Qualified	Contact Manufacturer

Conductor

Conductor Size	12 - 10 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size
Conductor Range	#12 AWG to #10 AWG

Configuration

Connector Type	Seamless Butt Splice
----------------	----------------------

Dimensions

Package Length	4.000 in
Package Width	3.000 in
Package Weight	0.415 lb.
Dimension - L Length Overall	41 mm
Package Height	1.500 in
Dimension - Inside Diameter	0.25 in
Dimension - Strip Length inch	23/64 in
Dimension - Length Overall	1.60 in

General

Sub Brand	TERMINALS, HYDENT
Insulation Type	Heat Shrink
Trade Name	HYDENT™
Plated	Y
Insulation	Y
Type	YSE-HHS
UPC 14 Digit GTIN	00781810525470
Material	Copper
Plating Type	Tin
UPC	781810525470

Logistics

Minimum Pack Quantity	50
Carton Quantity	100
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)