




YSE10HN, Nylon Splice For 12 - 10 AWG

By Burndy
Catalog # [YSE10HN](#)

Nylon Splice For 12 - 10 AWG

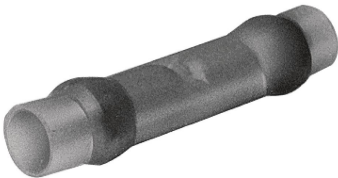

Features

- Manufactured from tin plated, seamless electrolytic copper tubing with integral barrel/insulation grip - providing maximum conductivity and tensile strength along with excellent cable support and strain relief
- Split heavy wall insulation grip for stronger insulation grip and strain relief
- Smooth funnel entry for easy wire insertion
- Transparent nylon insulation for easy wire insertion

Application

For Heavy Duty Application Requirements

Specifications

Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Contact Manufacturer
Certification - UL Recognized	No
Industry Standard(s)	UL486
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - Industry Standards Met	UL486
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	Yes
UL Listed	Yes

Conductor

Conductor - Copper Str Size	• 12 AWG • 10 AWG
Conductor Size	12 - 10 AWG
Conductor - Copper Str Size Range	12 AWG-10 AWG
Conductor Type	CU C Str-Size

Configuration

Connector Type	Seamless Butt Splice
----------------	----------------------

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - Outside Diameter inch	0.23 in
Dimension - P inch	0.19 in
Dimension - Pad Width inch	0.22 in
Package Height	0.000 in
Dimension - Strip Length inch	3/8 in
Dimension - B Length fraction	20/69 in
Dimension - B Length inch	0.29 in
Dimension - Length Overall inch	1.64 in
Dimension - N inch	0.19 in

General

Insulation Type	Nylon
Trade Name	INSULINK™
Insulation	Y
Sub Brand	INSULINK
Color Code	Yellow
Plated	Y
Type	YSE-HN
UPC 12 Digit	781810803851
UPC 14 Digit GTIN	00781810803851
Material	Copper
Plating Type	Tin
UPC	781810803851

Logistics

Minimum Pack Quantity	1000
Carton Quantity	1000
Pallet Quantity	99999

Operational

Temperature Rating	105
--------------------	-----

Product Assets

[Catalog \[English\]](#)